


Kabel koneksi

VDOGH040VAS00.2E03STGH040VAS

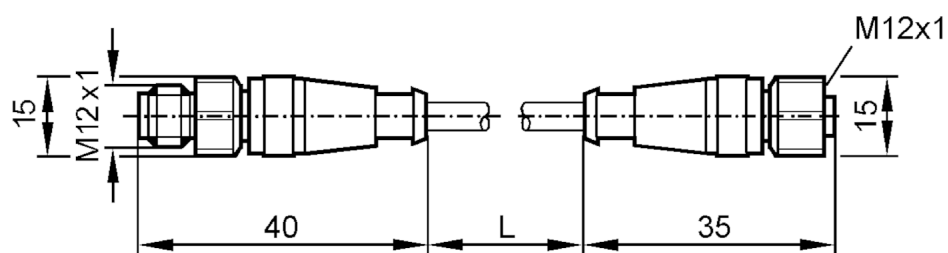

Aplikasi		
Fitur khusus		Kontak berlapis emas
Data kelistrikan		
Tegangan pengoperasian	[V]	< 300 AC/DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-20...105
Perlindungan		IP 68
Data teknis		
Berat	[g]	45.359
Dimensi	[mm]	15 x 15 x 40
Material		PVC
Material bodi detakan		PVC
Material mur		baja tahan karat (1.4571 / 316Ti)
Keterangan		
Jumlah paket		1 buah

**Kabel koneksi**

VDOGH040VAS00.2E03STGH040VAS

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PVC; Penguncian: baja tahan karat (1.4571 / 316Ti); Kontak: dilapisi emas

**Koneksi listrik**

Kabel: 0.2 m, PVC, abu-abu; 3 x 0.34 mm² / AWG 22

Koneksi**Koneksi listrik - soket**

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PVC; Penguncian: baja tahan karat (1.4571 / 316Ti); Kontak: dilapisi emas

