


Colokan adaptor

RSTGH050VAS00.3-05

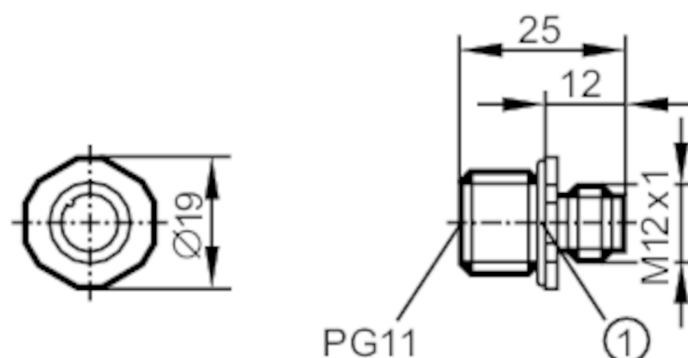

1 O-ring

Data kelistrikan

Tegangan pengoperasian [V] < 250 DC

Kondisi pengoperasian

Suhu sekitar [°C] -20...90

Data teknis

Berat [g] 54.431

Dimensi [mm] 19 x 19 x 25

Ulir pemasangan PG 11

Material baja tahan karat (1.4301/304)

Material bodi detakan baja tahan karat (1.4301/304)

Keterangan


Jumlah paket 1 buah

Koneksi listrik

Kabel: 0.5 m, PVC; 5 x 0.34 mm² / AWG 22

Koneksi listrik - colokan

Konektor: 1 x M12; pengkodean: A; Bodi cetakan: baja tahan karat (1.4301/304)

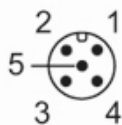

E18102



Colokan adaptor

RSTGH050VAS00.3-05

Koneksi

1	BN
2	WH
3	BU
4	BK
5	GY

	Warna core :
BK =	hitam
BN =	coklat
BU =	biru
GY =	abu-abu
WH =	putih