


E18104



Kabel koneksi dengan soket

ADOGH040VAS0100E04

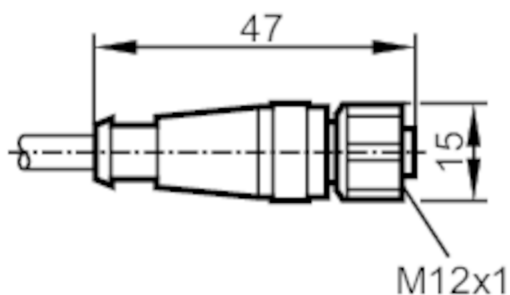

Aplikasi		
Fitur khusus		Kontak berlapis emas
Data kelistrikan		
Tegangan pengoperasian	[V]	< 300 AC/DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-20...105
Perlindungan		IP 68
Data teknis		
Berat	[g]	3764.814
Dimensi	[mm]	15 x 15 x 47
Material		PVC
Material bodi detakan		PVC
Material mur		baja tahan karat (1.4571 / 316Ti)
Keterangan		
Jumlah paket		1 buah

E18104



Kabel koneksi dengan soket


ADOGH040VAS0100E04

Koneksi listrik


Kabel: 100 m, PVC, abu-abu, Ø 5 mm; 4 x 0.34 mm² / AWG 22

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PVC; Penguncian: baja tahan karat (1.4571 / 316Ti); Kontak: dilapisi emas

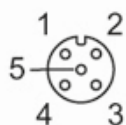

Koneksi

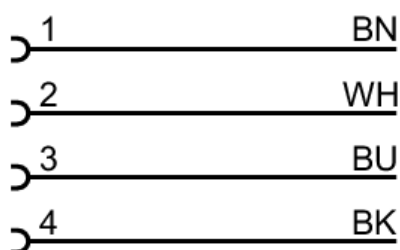

5: tidak digunakan

Warna core :

BK = hitam
BN = coklat
BU = biru
WH = putih