


Kabel koneksi dengan soket

ADOGH040VAS0012E04

Produk tidak tersedia - entri arsip

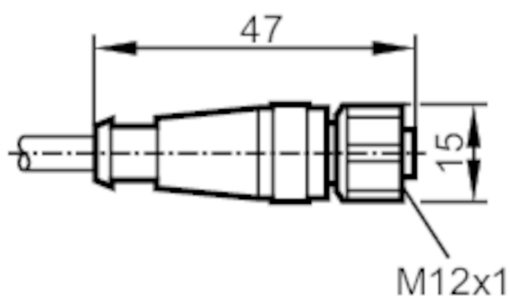

Aplikasi	
Fitur khusus	Kontak berlapis emas
Data kelistrikan	
Tegangan pengoperasian [V]	< 300 AC/DC
Kondisi pengoperasian	
Suhu sekitar [°C]	-20...105
Perlindungan	IP 68
Data teknis	
Berat [g]	299.371
Dimensi [mm]	15 x 15 x 47
Material	PVC
Material bodi detakan	PVC
Material mur	baja tahan karat (1.4571 / 316Ti)
Keterangan	
Jumlah paket	1 buah

E18106



Kabel koneksi dengan soket

ADOGH040VAS0012E04

Koneksi listrik

Kabel: 12 m, PVC, abu-abu, Ø 5 mm; 4 x 0.34 mm² / AWG 22

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PVC; Penguncian: baja tahan karat (1.4571 / 316Ti); Kontak: dilapisi emas



Koneksi



5: tidak digunakan

Warna core :

BK = hitam
BN = coklat
BU = biru
WH = putih