


Kabel koneksi

VDOGH040VAS00.5E03STGH040VAS

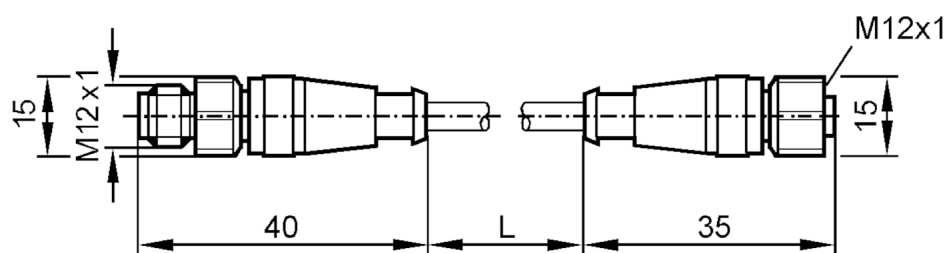

Aplikasi

Fitur khusus

Kontak berlapis emas

Data kelistrikan

Tegangan pengoperasian

[V]

< 300 AC/DC

Kondisi pengoperasian

Suhu sekitar

[°C]

-20...105

Perlindungan

IP 68

Data teknis

Berat

[g]

45.359

Dimensi

[mm]

15 x 15 x 40

Material

PVC

Material bodi detakan

PVC

Material mur

baja tahan karat (1.4571 / 316Ti)


Keterangan

Jumlah paket

1 buah

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PVC; Penguncian: baja tahan karat (1.4571 / 316Ti); Kontak: dilapisi emas

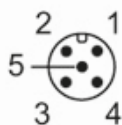




Kabel koneksi

VDOGH040VAS00.5E03STGH040VAS

Koneksi listrik

Kabel: 0.5 m, PVC, abu-abu; 3 x 0.34 mm² / AWG 22

Koneksi

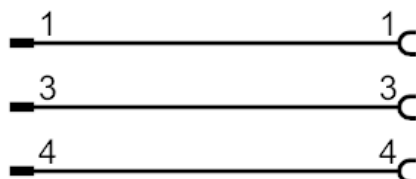

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PVC; Penguncian: baja tahan karat (1.4571 / 316Ti); Kontak: dilapisi emas

