




Kabel koneksi dengan soket


ADOGH140MSS0005A11

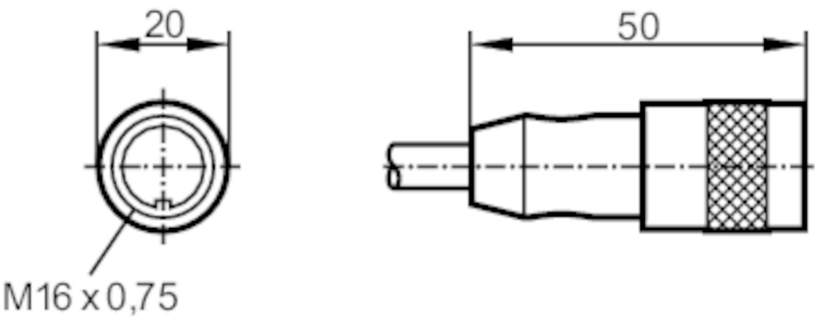

Data kelistrikan		
Tegangan pengoperasian	[V]	< 250 AC/DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...80
Perlindungan		IP 67
Data teknis		
Berat	[g]	635.029
Dimensi	[mm]	20 x 20 x 50
Material		PUR hitam
Material bodi detakan		PUR
Material mur		kuningan, berlapis nikel
Keterangan		
Jumlah paket		1 buah

Koneksi listrik	
Kabel: 5 m, PUR, hitam, Ø 9.3 mm; 8 x 0.5 mm² (63 x Ø 0.1 mm) + 3 x 1.0 mm² (127 x Ø 0.1 mm)	

Koneksi listrik - soket	
Konektor: 1 x M16, lurus; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel	

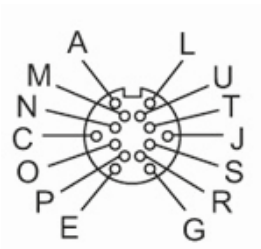


E18147



Kabel koneksi dengan soket

ADOGH140MSS0005A11

Koneksi

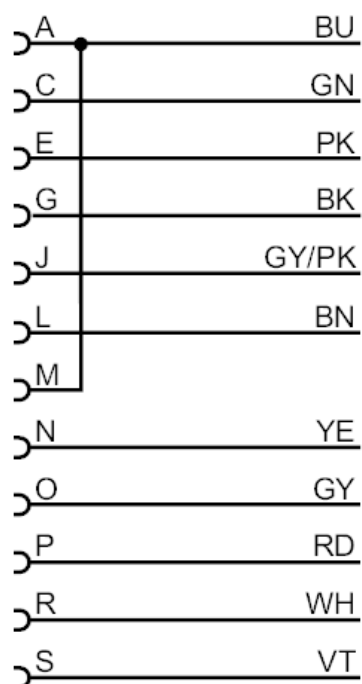

	Warna core :
BK =	hitam
BN =	coklat
BU =	biru
GN =	hijau
GY =	abu-abu
PK =	merah muda
RD =	merah
VT =	ungu
WH =	putih
YE =	kuning