


E18158



Kabel koneksi dengan soket

ADOAH040VAS0030E04

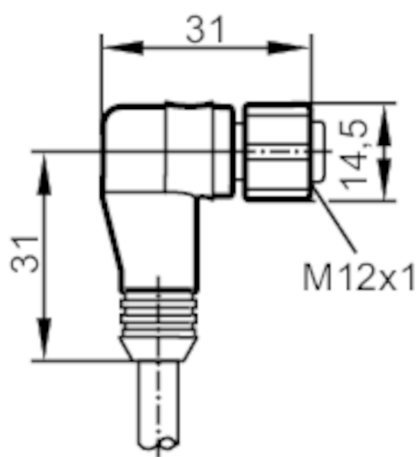

Aplikasi	
Fitur khusus	Kontak berlapis emas
Data kelistrikan	
Tegangan pengoperasian [V]	< 300 AC/DC
Kondisi pengoperasian	
Suhu sekitar [°C]	-20...105
Perlindungan	IP 68
Data teknis	
Berat [g]	1088.621
Dimensi [mm]	31 x 14.5 x 31
Material	PVC
Material bodi detakan	PVC
Material mur	baja tahan karat (1.4571 / 316Ti)
Keterangan	
Jumlah paket	1 buah

**Kabel koneksi dengan soket**

ADOAH040VAS0030E04

Koneksi listrikKabel: 30 m, PVC, abu-abu; 4 x 0.34 mm² / AWG 22**Koneksi listrik - soket**

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: PVC; Penguncian: baja tahan karat (1.4571 / 316Ti); Kontak: dilapisi emas

**Koneksi**

5: tidak digunakan
Warna core :
BK = hitam
BN = coklat
BU = biru
WH = putih