




Kabel koneksi

VDOAH040VAS02.5E03STGH040VAS

Produk tidak tersedia - entri arsip

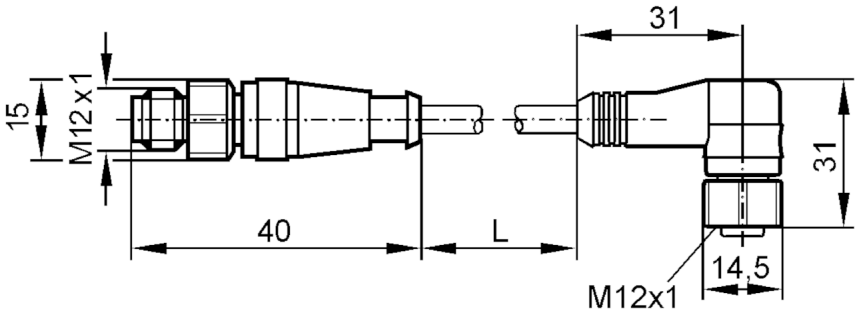

Aplikasi	
Fitur khusus	Kontak berlapis emas
Data kelistrikan	
Tegangan pengoperasian [V]	< 300 AC/DC
Kondisi pengoperasian	
Suhu sekitar [°C]	-20...105
Perlindungan	IP 68
Data teknis	
Berat [g]	63.503
Material	TPE
Material bodi detakan	TPE
Material mur	baja tahan karat (1.4571 / 316Ti)
Keterangan	
Jumlah paket	1 buah

**Kabel koneksi**


VDOAH040VAS02.5E03STGH040VAS

Koneksi listrikKabel: 2.5 m, PVC, abu-abu; 3 x 0.34 mm² / AWG 22**Koneksi listrik - colokan**

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPE; Penguncian: baja tahan karat (1.4571 / 316Ti); Kontak: dilapisi emas

**Koneksi listrik**

Koneksi

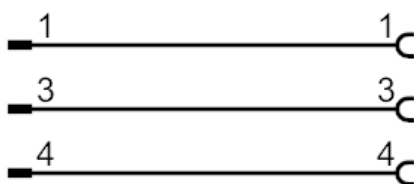**Koneksi listrik - soket**

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: TPE; Penguncian: baja tahan karat (1.4571 / 316Ti); Kontak: dilapisi emas

