


E18247




Kabel koneksi

VDOGA050MSS0.15E04STGA040MSS

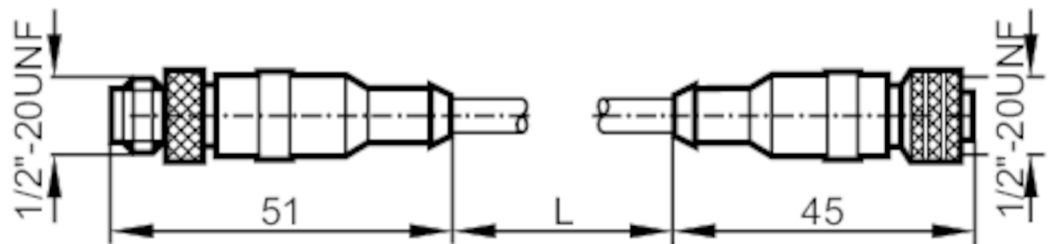


Aplikasi		
Fitur khusus		Bebas dari silikon; Bebas halogen; Kontak berlapis emas
Bebas dari silikon		ya
Data kelistrikan		
Tegangan pengoperasian	[V]	< 60 AC / < 75 DC
Total beban arus maks.	[A]	3
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...85
Perlindungan		IP 68
Data teknis		
Berat	[g]	22.68
Material		PUR
Material bodi detakan		PUR
Material mur		kuningan, berlapis nikel
Keterangan		
Jumlah paket		1 buah
Koneksi listrik - colokan		

Konektor: 1 x 1/2", lurus; pengkodean: C; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas

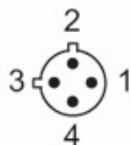

Kabel koneksi

VDOGA050MSS0.15E04STGA040MSS

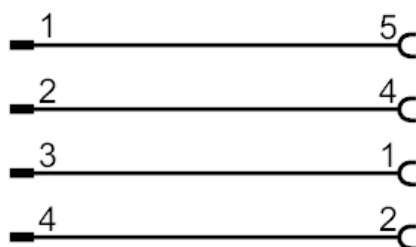Koneksi listrikKabel: 0.3 m, PUR, Bebas halogen, hitam, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)**Koneksi****Koneksi listrik - soket**

Konektor: 1 x 1/2", lurus; pengkodean: C; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas

