


Colokan adaptor

RSTGA030ALS00.3-03

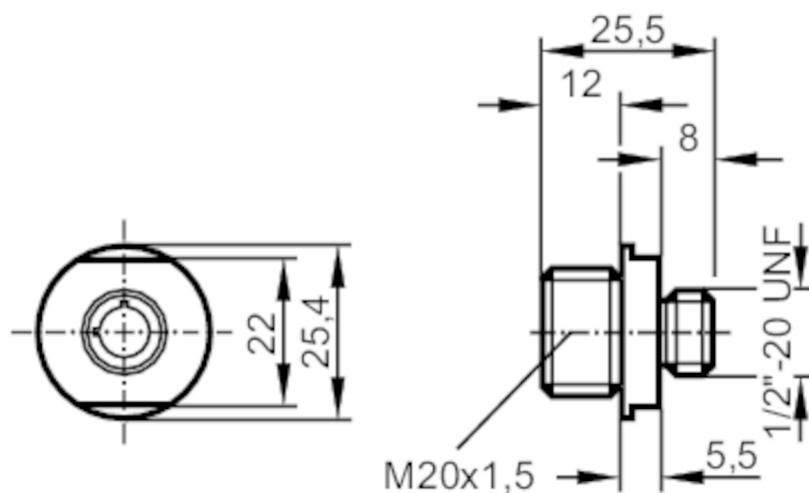

1 O-ring

Aplikasi

Fitur khusus

Kontak berlapis emas

Data kelistrikan

Tegangan pengoperasian

[V]

< 250 AC/DC

Kondisi pengoperasian

Suhu sekitar

[°C]

-20...80

Perlindungan

IP 68

Data teknis

Berat

[g]

387.821

Ulir pemasangan

M20 x 1,5

Material

kuningan berlapis nikel

Material bodi detakan

kuningan, berlapis nikel

Keterangan

Jumlah paket

1 buah

E18251



Colokan adaptor

RSTGA030ALS00.3-03

Koneksi listrik

Kabel: 0.3 m, PVC; 3 x 0.34 mm² / AWG 22

Koneksi listrik - colokan

Konektor: 1 x 1/2", lurus; pengkodean: C; Bodi cetakan: kuningan, berlapis nikel; Kontak: dilapisi emas



Koneksi

1	GN
2	RD/BK
3	RD/WH

BK =	Warna core :	hitam
GN =		hijau
RD =		merah
WH =		putih