




Soket adaptor


RDOGH050MSS00.3E05

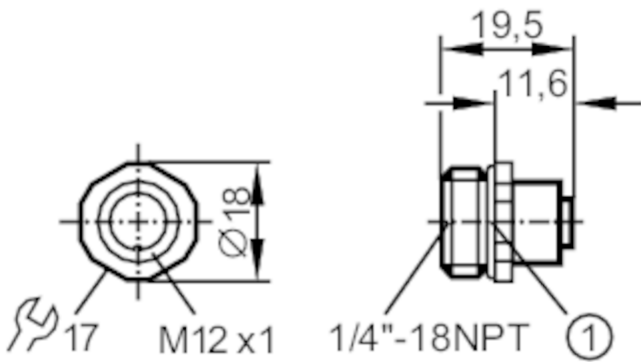

1 O-ring

Data kelistrikan		
Tegangan pengoperasian	[V]	< 250 AC/DC
Total beban arus maks.	[A]	4
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 68
Data teknis		
Berat	[g]	22.68
Ulir pemasangan		1/4"-18NPT
Material		kuningan berlapis nikel
Material bodi detakan		kuningan, berlapis nikel
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
Kabel: 0.5 m, PVC; 5 x 0.34 mm²		
Koneksi listrik - soket		

Konektor: 1 x M12; pengkodean: A; Bodi cetakan: kuningan, berlapis nikel

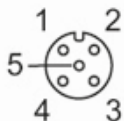


E18327



Soket adaptor

RDOGH050MSS00.3E05

Koneksi

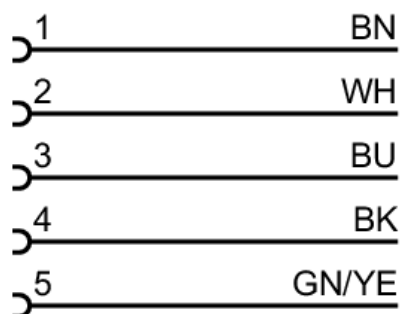

	Warna core :
BK =	hitam
BN =	coklat
BU =	biru
GN/YE =	hijau/kuning
WH =	putih