


E19901



Kotak splitter

ZDO6H040MSS0010A09

Produk tidak tersedia - entri arsip

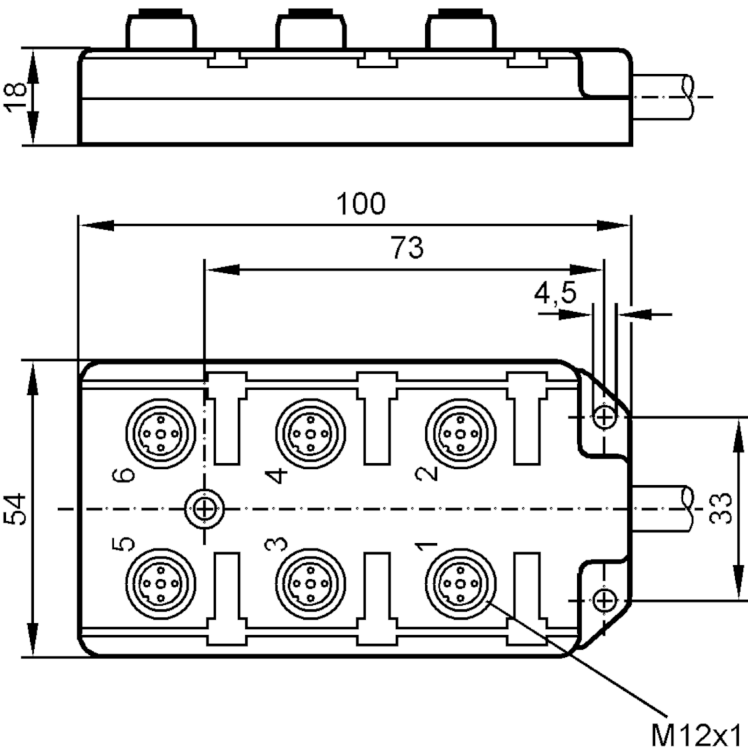

Data kelistrikan		
Tegangan pengoperasian	[V]	10...110 AC/DC
Beban arus maks. per modul/ slot	[A]	4
Total beban arus maks.	[A]	12
Kondisi pengoperasian		
Suhu sekitar	[°C]	-15...90
Perlindungan		IP 67
Data teknis		
Dimensi	[mm]	18 x 54 x 100
Jumlah port kotak splitter		6
Keterangan		
Jumlah paket		1 buah



Kotak splitter

ZDO6H040MSS0010A09

Koneksi listrik

Kabel: 10 m, PUR / PVC; 6 x 0.34 mm² + 3 x 0.75 mm²

Koneksi listrik - slot

Konektor: 6 x M12; pengkodean: A



Koneksi

BN	1 (1...6)
BU	3 (1...6)
GN/YE	5 (1...6)
WH	4 (1)
GN	4 (2)
YE	4 (3)
GY	4 (4)
PK	4 (5)
RD	4 (6)

	Warna core :
BN =	coklat
BU =	biru
GN =	hijau
GN/YE =	hijau/kuning
GY =	abu-abu
PK =	merah muda
RD =	merah
WH =	putih
YE =	kuning