


E19902



Splitter Y

ZDO2H045MSS0010B05

Produk tidak tersedia - entri arsip

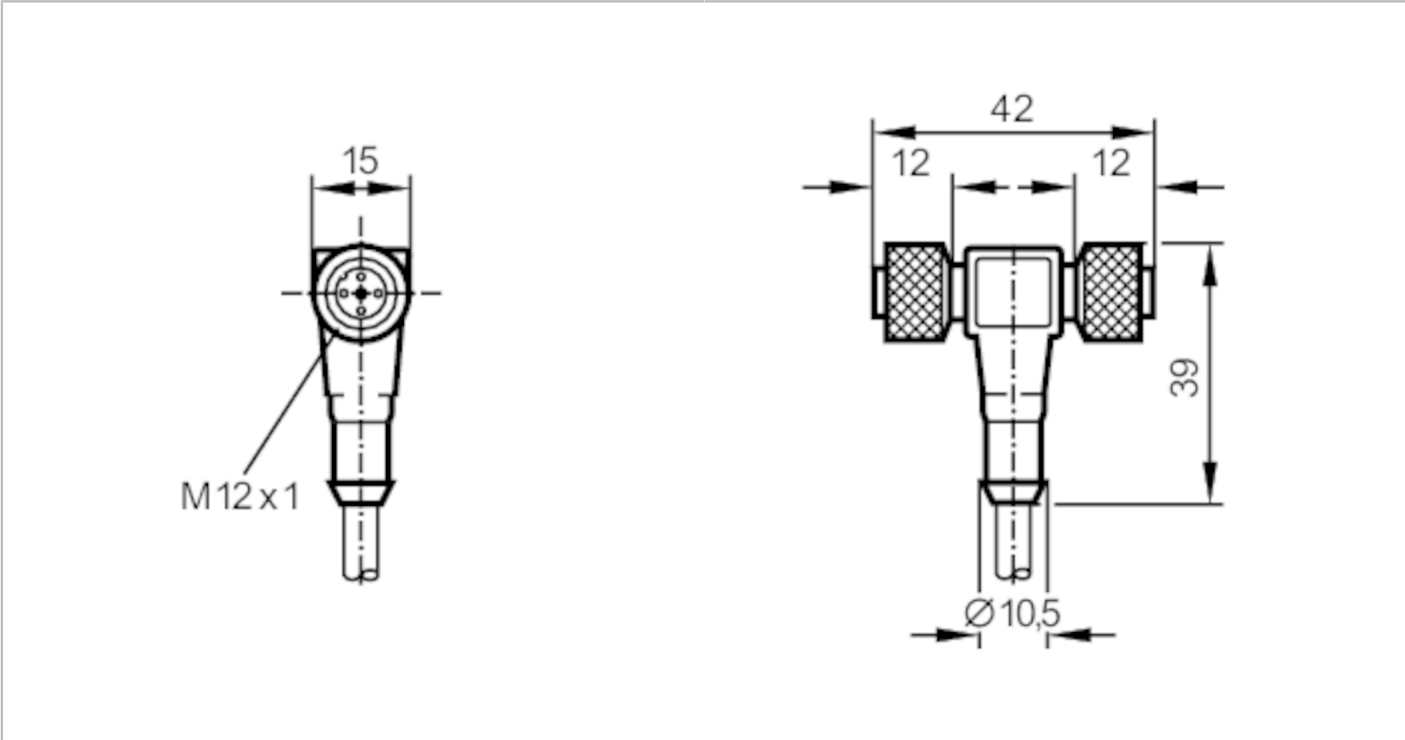

Data kelistrikan		
Tegangan pengoperasian	[V]	< 125 AC / < 150 DC
Beban arus maks. per modul/ slot	[A]	4
Total beban arus maks.	[A]	4
Kondisi pengoperasian		
Suhu sekitar	[°C]	-15...90
Perlindungan		IP 67
Data teknis		
Material		TPU
Keterangan		
Jumlah paket		1 buah




Splitter Y

ZDO2H045MSS0010B05

Koneksi listrik

Kabel: 10 m, PUR / PVC, oranye, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Koneksi

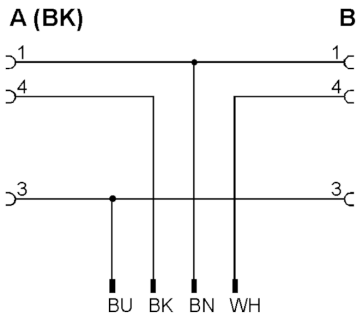

Warna core :
BK = hitam
BN = coklat
BU = biru
WH = putih