


E20430



Kabel koneksi dengan soket

ADOGB030MSS0002E03

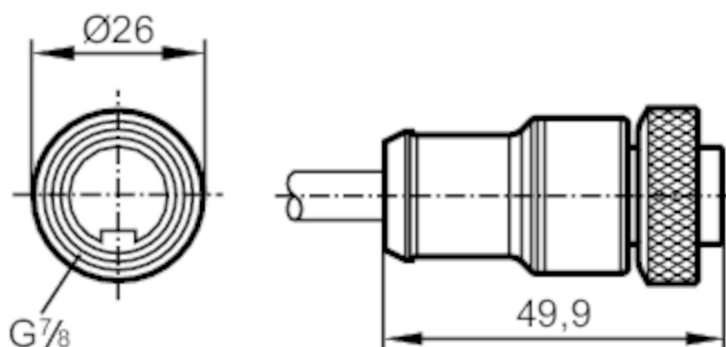

Data kelistrikan

Tegangan pengoperasian	[V]	< 300 AC/DC
------------------------	-----	-------------

Kondisi pengoperasian

Suhu sekitar	[°C]	-30...80
Suhu sekitar (bergerak)	[°C]	-5...80
Perlindungan		IP 68

Data teknis

Berat	[g]	117.5
Dimensi	[mm]	26 x 26 x 49.9
Material bodi detakan		TPU
Material mur		seng tuang

Keterangan


Jumlah paket		1 buah
--------------	--	--------

**Kabel koneksi dengan soket**

AD0GB030MSS0002E03

Koneksi listrikKabel: 2 m, PVC, hitam, Ø 5.4 mm; 3 x 0.5 mm²**Koneksi listrik - soket**

Konektor: 1 x 7/8", lurus; Bodi cetakan: TPU; Penguncian: seng tuang

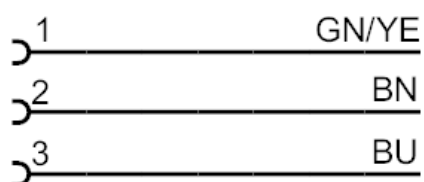**Koneksi**

BN = Warna core :
BU = coklat
GN/YE = biru
 hijau/kuning