




Kabel koneksi dengan soket


ADOGB030PLS0005E03

Produk tidak tersedia - entri arsip

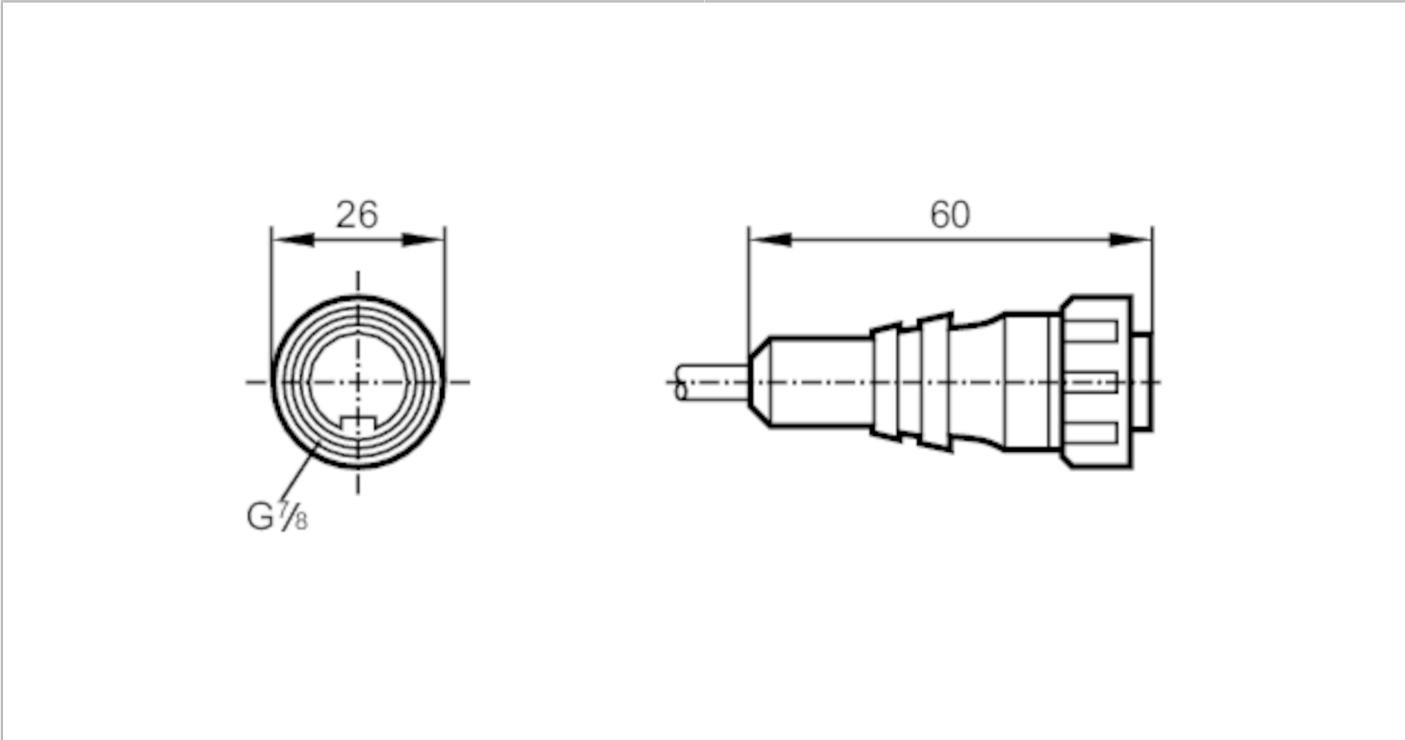

Data kelistrikan		
Tegangan pengoperasian	[V]	10...30 DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-40...90
Perlindungan		IP 68
Data teknis		
Dimensi	[mm]	26 x 26 x 60
Material		TPU
Material bodi detakan		TPU
Material mur		TPU
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
Kabel: 5 m, PVC, oranye, Ø 5.2 mm; 3 x 0.75 mm² (22 x Ø 0.2 mm)		
Koneksi listrik - soket		

Konektor: 1 x 7/8", lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: TPU

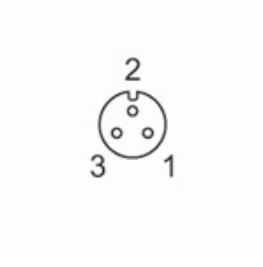


E20431



Kabel koneksi dengan soket

ADOGB030PLS0005E03

Koneksi

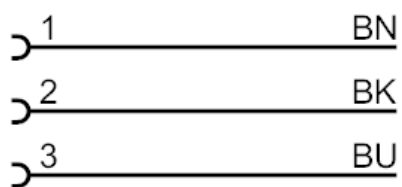

BK =	Warna core :	hitam
BN =		coklat
BU =		biru