




Sensor sinar tembus fiber optik

FE-00-P-A-R3/0,18M +10MM

Produk tidak tersedia - entri arsip

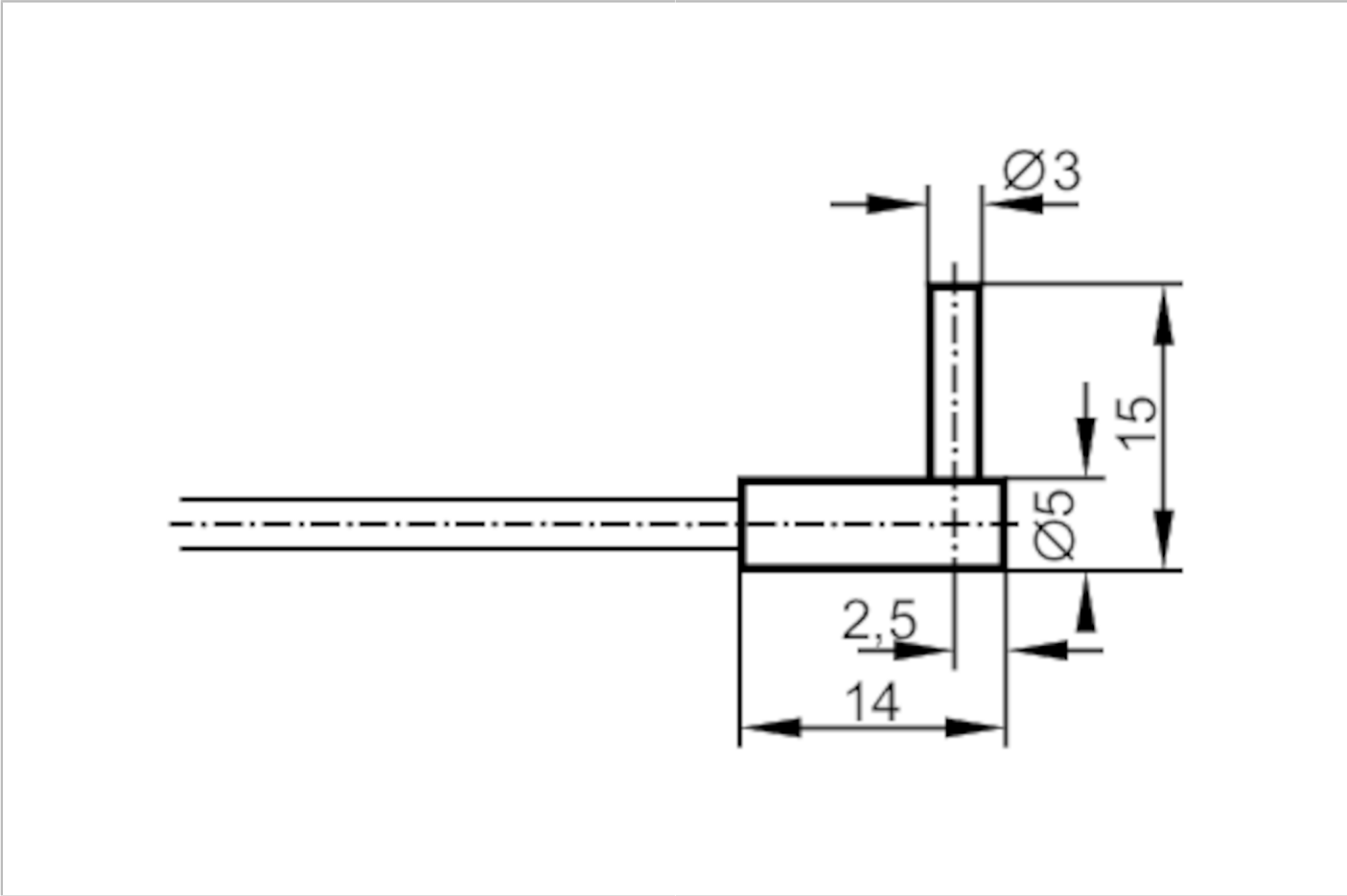

Aplikasi		
Prinsip fungsi		Sensor sinar tembus
Zona pendeteksian		
Jangkauan dengan tipe amplifier fiber optik		OKF; OUF
OKF		
Jangkauan fiber optik	[mm]	40
OUF		
Jangkauan fiber optik	[mm]	40
Kondisi pengoperasian		
Suhu sekitar	[°C]	-20...80
Data teknis		
Versi kepala pendeteksian		bersiku
Diameter kepala pendeteksian	[mm]	3
Panjang kepala pendeteksian	[mm]	10
Panjang total	[mm]	180; (+10 mm)
Radius pembengkokan min.	[mm]	10
Material		Adaptor: PPE

E20450



Sensor sinar tembus fiber optik

FE-00-P-A-R3/0,18M +10MM

Material fiber	kaca
Material kepala fiber	aluminium
Material selubung fiber	PVC
Keterangan	
Jumlah paket	1 buah