




Sensor refleksi difus fiber optik

FT-00-P-A-R4/0,14M

Produk tidak tersedia - entri arsip

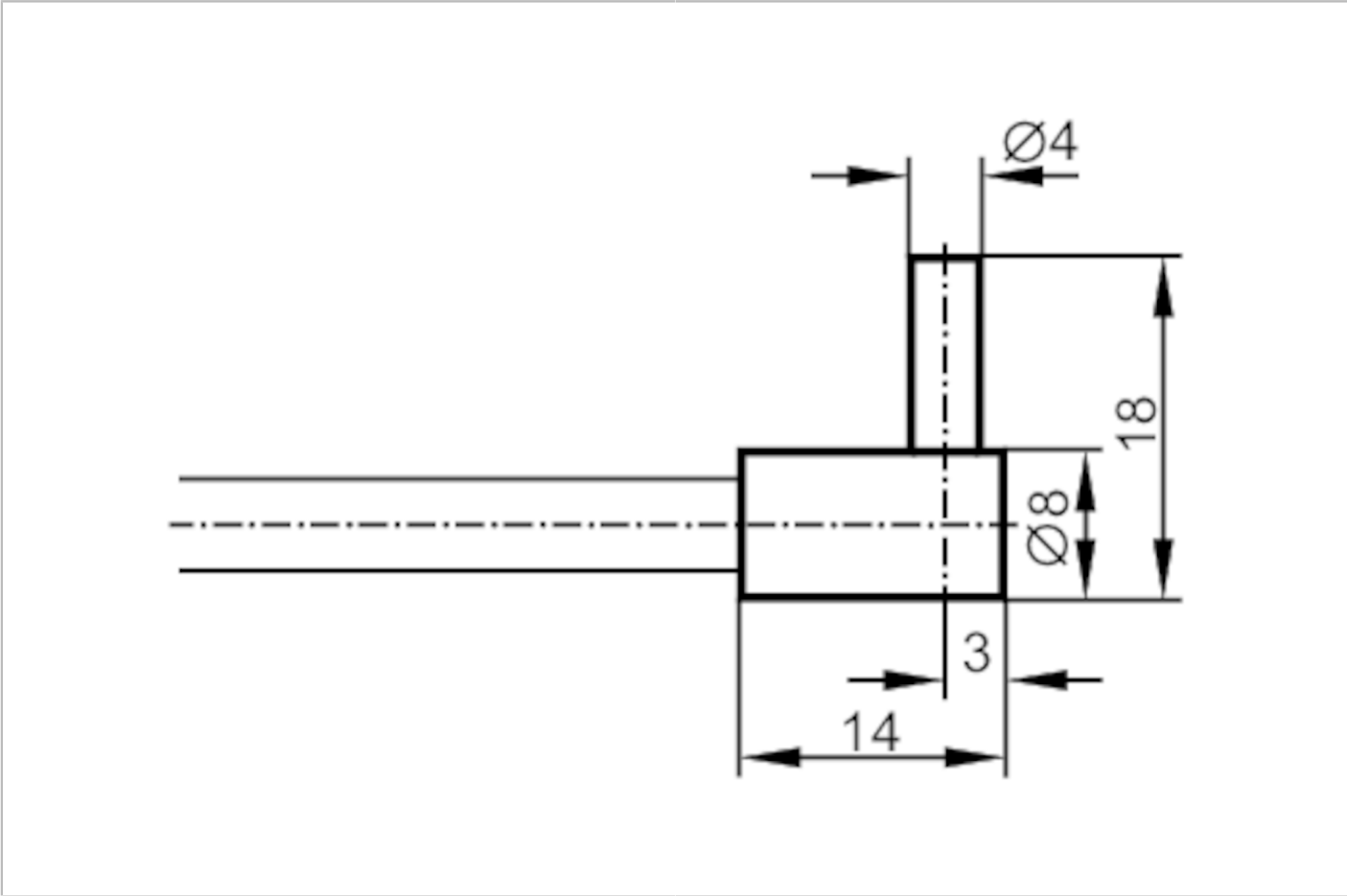

Aplikasi		
Prinsip fungsi		Sensor refleksi difus
Zona pendeteksian		
Jangkauan dengan tipe amplifier fiber optik		OKF; OUF
OKF		
Jangkauan fiber optik	[mm]	40
OUF		
Jangkauan fiber optik	[mm]	40
Kondisi pengoperasian		
Suhu sekitar	[°C]	-20...150
Data teknis		
Versi kepala pendeteksian		bersiku
Diameter kepala pendeteksian	[mm]	4
Panjang kepala pendeteksian	[mm]	10
Panjang total	[mm]	100; (+10 mm)
Radius pembengkokan min.	[mm]	20
Material fiber		kaca

E20566



Sensor refleksi difus fiber optik

FT-00-P-A-R4/0,14M

Material kepala fiber	baja tahan karat (1.4305/303)
Material selubung fiber	silikon logam
Keterangan	
Jumlah paket	1 buah