


Sensor sinar tembus fiber optik

FE-11-EPA-M4/F1X1/2M

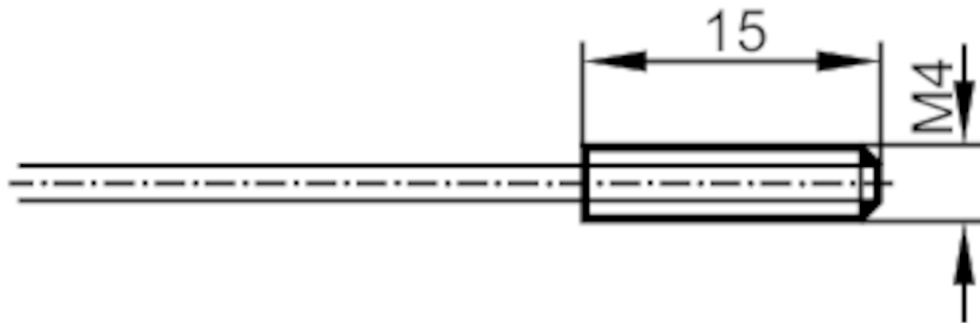

Aplikasi		
Prinsip fungsi	Sensor sinar tembus	
Aplikasi	Untuk digunakan di lingkungan industri	
Zona pendeteksian		
Jangkauan dengan tipe amplifier fiber optik	OB50; OBF; OCF; OO50	
OB50		
Jangkauan fiber optik	[mm]	200
OBF		
Jangkauan fiber optik	[mm]	450
OCF (High Power)		
Jangkauan fiber optik	[mm]	2800
OO50		
Jangkauan fiber optik	[mm]	800
Kondisi pengoperasian		
Suhu sekitar	[°C]	-40...70
Data teknis		
Berat	[g]	47.5
Versi kepala pendeteksian	lurus	
Ulir kepala pendeteksian	M4	

E20606



Sensor sinar tembus fiber optik

FE-11-EPA-M4/F1X1/2M

Panjang kepala pendeteksian [mm]	15
Panjang total [mm]	2000
Radius pembengkokan min. [mm]	30
Susunan fiber	
Diameter core [mm]	1
Material fiber	PMMA
Material kepala fiber	aluminium
Material selubung fiber	PE

Aksesori

Item dikirim	mur segi enam: 4 x M4 washer pengunci bergerigi: 4
Aksesori (opsional)	Pemotong untuk fiber optik:, E20600

Keterangan

Jumlah paket	1 buah
--------------	--------