


Sensor sinar tembus fiber optik

FE-11-EPA-M4/F16X0,265/2M

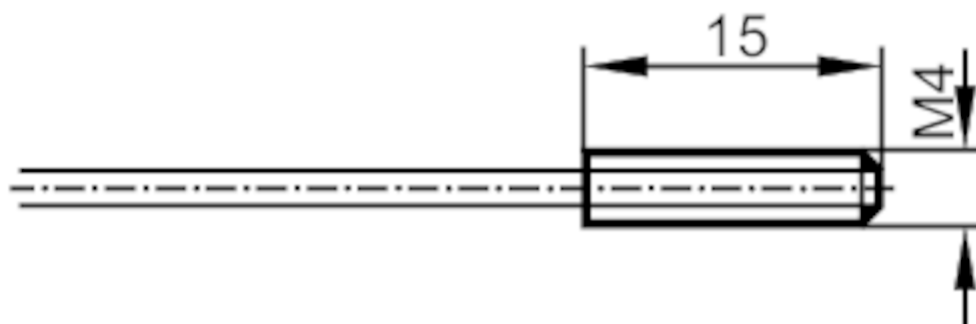

Aplikasi

Prinsip fungsi

Sensor sinar tembus

Aplikasi

Radius pembengkokan kecil

Zona pendeteksian

Jangkauan dengan tipe
amplifier fiber optik

OB50; OBF; OCF; OO50

OB50

Jangkauan fiber optik

[mm]

150

OBF

Jangkauan fiber optik

[mm]

210

OCF (High Power)

Jangkauan fiber optik

[mm]

2590

OO50

Jangkauan fiber optik

[mm]

800

Kondisi pengoperasian

Suhu sekitar

[°C]

-40...70

Data teknis

Berat

[g]

47

Versi kepala pendeteksian

lurus

Ulir kepala pendeteksian

M4

E20615



Sensor sinar tembus fiber optik

FE-11-EPA-M4/F16X0,265/2M

Panjang kepala pendeteksian [mm]	15
Panjang total [mm]	2000
Radius pembengkokan min. [mm]	9
Susunan fiber	
Diameter core [mm]	16 x 0.25
Material fiber	PMMA
Material kepala fiber	aluminium
Material selubung fiber	PE

Aksesori

Item dikirim	mur segi enam: 4 x M4 washer pengunci bergerigi: 4
Aksesori (opsional)	Pemotong untuk fiber optik:, E20600

Keterangan

Jumlah paket	1 buah
--------------	--------