




Colokan adaptor

ADAPTER PLUG US-100

Produk tidak tersedia - entri arsip

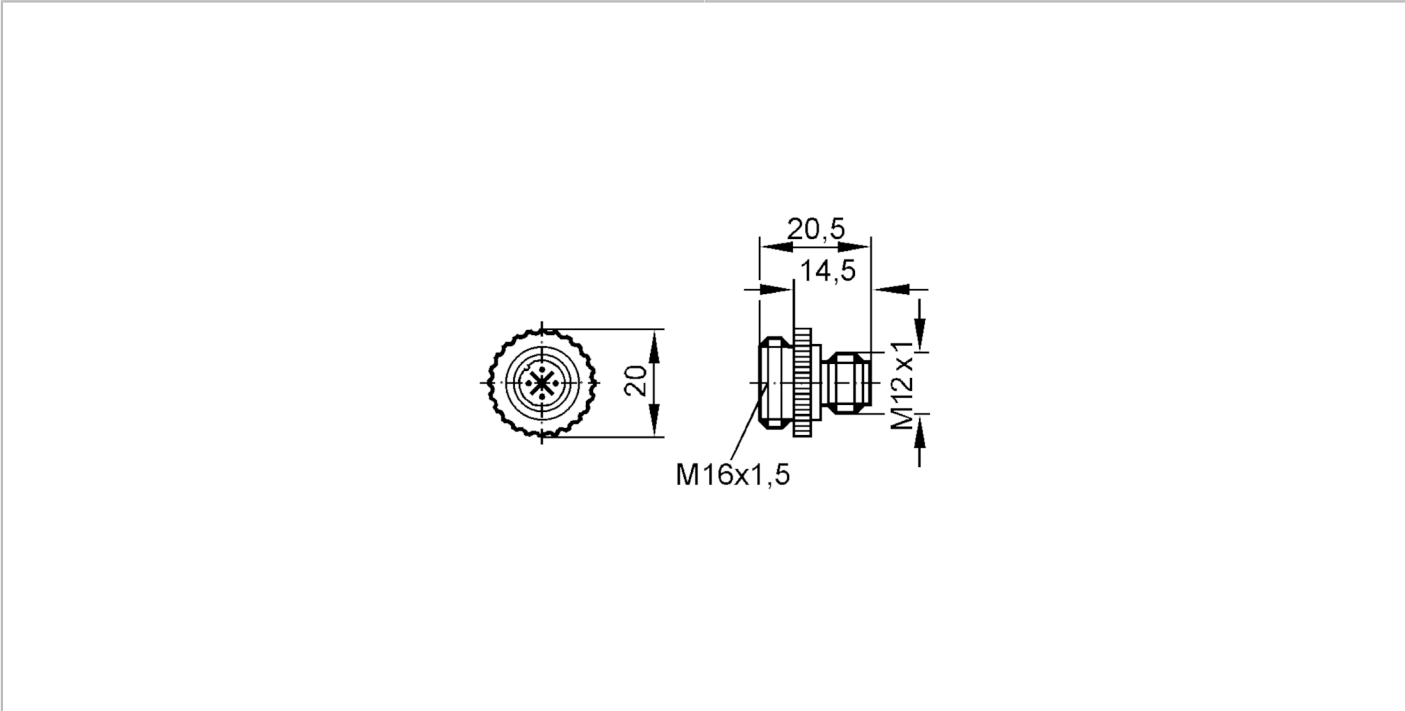

Data kelistrikan

Tegangan pengoperasian [V] < 250 AC / < 300 DC

Kondisi pengoperasian

Suhu sekitar [°C] -40...85

Perlindungan IP 67

Data teknis

Berat [g] 0.013

Ulir pemasangan M16

Material kuningan berlapis nikel

Material bodi detakan kuningan, berlapis nikel

Keterangan

Jumlah paket 1 buah

Koneksi listrik

Kabel: 0.065 m, PVC; 4 x 0.34 mm²

Koneksi listrik - colokan

Konektor: 1 x M12; pengkodean: A; Bodi cetakan: kuningan, berlapis nikel





Colokan adaptor

ADAPTER PLUG US-100

Koneksi

1	BN
2	WH
3	BU
4	BK

	Warna core :
BK =	hitam
BN =	coklat
BU =	biru
WH =	putih