


Sensor sinar tembus fiber optik

FE-11-E-V-E3R/2m

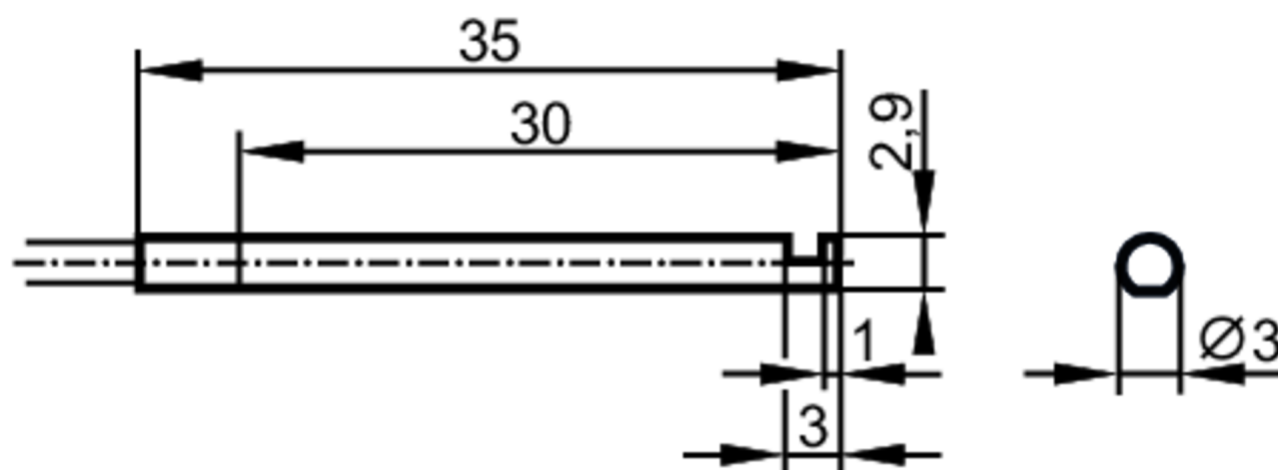

Aplikasi		
Desain		defleksi 90° dari sinar cahaya
Prinsip fungsi		Sensor sinar tembus
Aplikasi		Untuk digunakan di lingkungan industri
Zona pendeteksian		
Jangkauan dengan tipe amplifier fiber optik		OB50; OBF; OCF; OO50
OB50		
Jangkauan fiber optik	[mm]	140
OBF		
Jangkauan fiber optik	[mm]	230
OCF (High Power)		
Jangkauan fiber optik	[mm]	1720
OO50		
Jangkauan fiber optik	[mm]	400
Kondisi pengoperasian		
Suhu sekitar	[°C]	-40...70
Data teknis		
Berat	[g]	58.5
Versi kepala pendeteksian		bersiku

E20714



Sensor sinar tembus fiber optik

FE-11-E-V-E3R/2m

Diameter kepala pendeteksian	[mm]	3
Panjang total	[mm]	2000
Radius pembengkokan min.	[mm]	25
Susunan fiber		●
Material fiber		PMMA
Material kepala fiber		baja tahan karat (1.4305/303)
Material selubung fiber		PE
Aksesori		
Item dikirim		Klem pemasangan:, E20107
Keterangan		
Jumlah paket		1 buah