


E20738



Kabel koneksi dengan soket

ADOGH080MSS0002B08

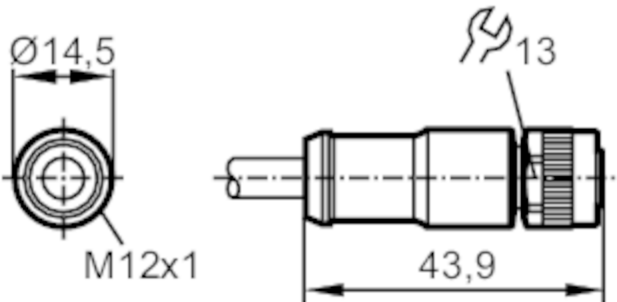

Aplikasi		
Fitur khusus		Kabel berpelindung
Data kelistrikan		
Tegangan pengoperasian	[V]	< 60 AC/DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...85
Perlindungan		IP 67
Data teknis		
Berat	[g]	125.5
Dimensi	[mm]	14.5 x 14.5 x 43.9
Material		TPU
Material bodi detakan		TPU
Material mur		seng tuang, berlapis nikel
Keterangan		
Jumlah paket		1 buah

E20738



Kabel koneksi dengan soket


ADOGH080MSS0002B08

Koneksi listrik

Kabel: 2 m, PUR, hitam, berpelindung; 7 x 0.25 mm² (14 x Ø 0.15 mm)

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: seng tuang, berlapis nikel

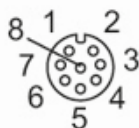

Koneksi

1	WH
2	BN
3	GN
4	YE
5	GY
6	PK
7	BU
8	screen

warna sesuai DIN
47100

Warna core :

BN =	coklat
BU =	biru
GN =	hijau
GY =	abu-abu
PK =	merah muda
WH =	putih
YE =	kuning
screen =	penutup