


Sensor sinar tembus fiber optik

FE-11-EPA-Q-/F16X0,265

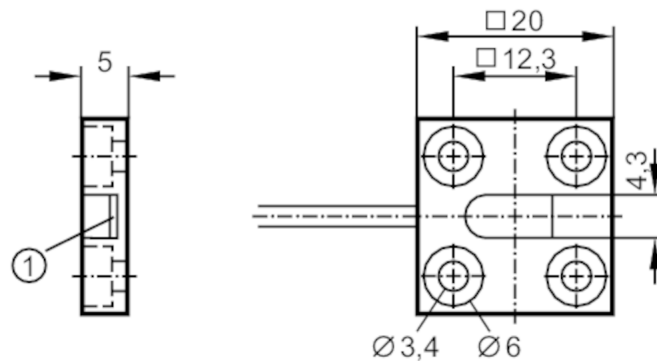

1 emisi cahaya

Aplikasi

Desain	Konverter penampang
Prinsip fungsi	Sensor sinar tembus
Aplikasi	Radius pembungkakan kecil

Zona pendeteksian

Jangkauan dengan tipe amplifier fiber optik	OB50; OBF; OCF; OO50
---	----------------------

OB50

Jangkauan fiber optik [mm]	150
----------------------------	-----

OBF

Jangkauan fiber optik [mm]	300
----------------------------	-----

OCF (High Power)

Jangkauan fiber optik [mm]	2040
----------------------------	------

OO50

Jangkauan fiber optik [mm]	700
----------------------------	-----

Kondisi pengoperasian

Suhu sekitar [°C]	-40...70
-------------------	----------

Data teknis

Berat [g]	61
Tinggi kepala pendeteksian [mm]	5
Lebar kepala pendeteksian [mm]	20
Panjang kepala pendeteksian [mm]	20
Dimensi probe [mm]	5 x 20 x 20
Panjang total [mm]	2000
Radius pembungkakan min. [mm]	9
Susunan fiber	
Diameter core [mm]	16 x 0.25
Material fiber	PMMA
Material kepala fiber	aluminium
Material selubung fiber	PE

E20757



Sensor sinar tembus fiber optik

FE-11-EPA-Q-/F16X0,265

Aksesori

Aksesori (opsional)

Pemotong untuk fiber optik:, E20600

Keterangan

Jumlah paket

1 buah