




Sensor refleksi difus fiber optik

FT-50-V-V-R5

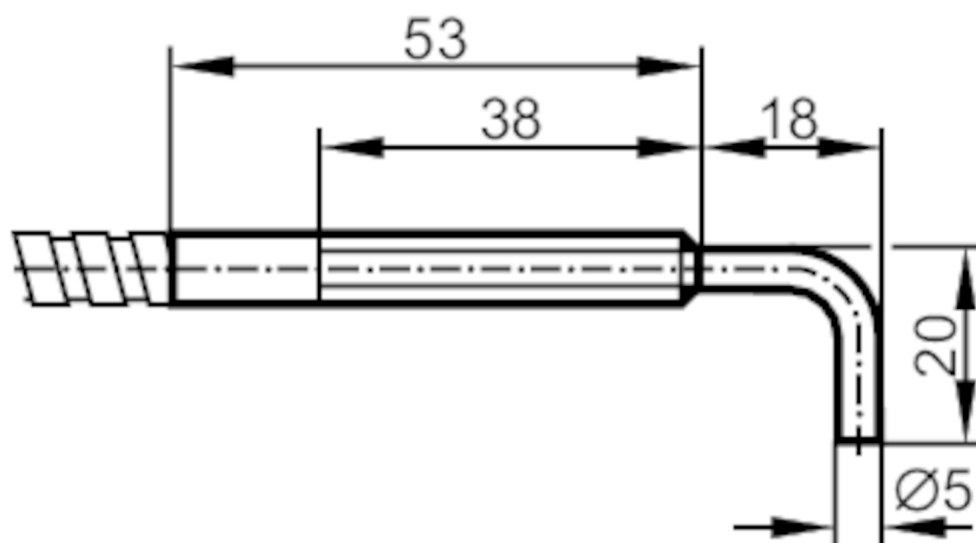

Aplikasi

Prinsip fungsi	Sensor refleksi difus
----------------	-----------------------

Zona pendeteksian

Jangkauan dengan tipe amplifier fiber optik	OBF; ODF; OMF
---	---------------

OBF

Jangkauan fiber optik [mm]	150
----------------------------	-----

ODF

Jangkauan fiber optik [mm]	1
----------------------------	---

OMF

Jangkauan fiber optik [mm]	175
----------------------------	-----

Kondisi pengoperasian

Suhu sekitar [°C]	-58...315
-------------------	-----------

Data teknis

Berat [g]	126
Versi kepala pendeteksian	bersiku
Diameter kepala pendeteksian [mm]	5
Panjang total [mm]	900
Radius pembengkokan min. [mm]	19
Susunan fiber	①

E20826



Sensor refleksi difus fiber optik

FT-50-V-V-R5

Material fiber	kaca
Material kepala fiber	baja tahan karat (1.4305/303)
Material selubung fiber	baja tahan karat (1.4305/303)
Aksesori	
Item dikirim	mur pengunci: 2
	Washer pegas: 2
Keterangan	
Jumlah paket	1 buah