




Sensor sinar tembus fiber optik

FE-50-V-V-R5

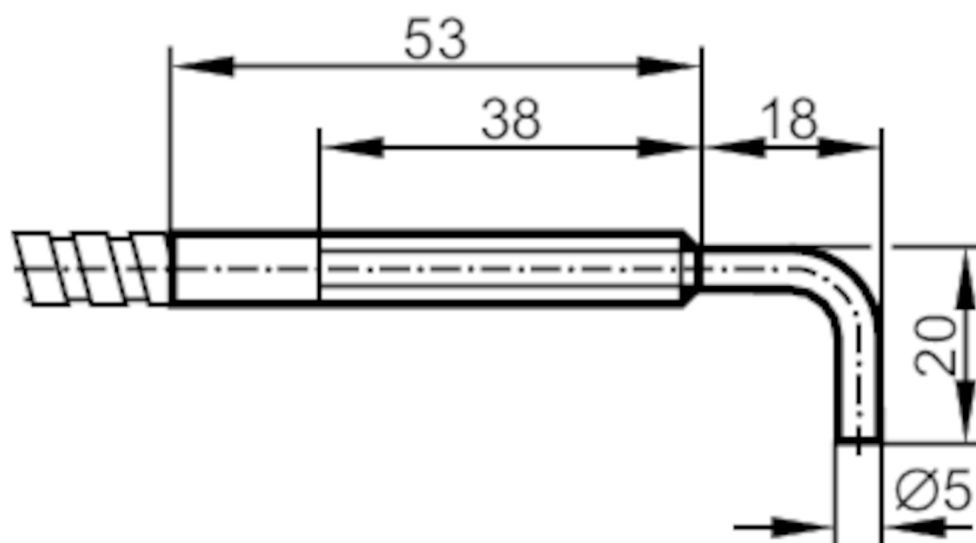

Aplikasi

Prinsip fungsi Sensor sinar tembus

Zona pendeteksian

Jangkauan dengan tipe amplifier fiber optik OBF; ODF; OMF

OBF

Jangkauan fiber optik [mm] 1000

ODF

Jangkauan fiber optik [mm] 4

OMF

Jangkauan fiber optik [mm] 800

Kondisi pengoperasian

Suhu sekitar [°C] -58...315

Data teknis

Berat [g] 196

Versi kepala pendeteksian bersiku

Diameter kepala pendeteksian [mm] 5

Panjang total [mm] 900

Radius pembengkokan min. [mm] 19

Susunan fiber



Sensor sinar tembus fiber optik

FE-50-V-V-R5

Material fiber	kaca
Material kepala fiber	baja tahan karat (1.4305/303)
Material selubung fiber	baja tahan karat (1.4305/303)
Aksesori	
Item dikirim	mur pengunci: 2
	Washer pegas: 2
Keterangan	
Jumlah paket	1 buah