


Sensor sinar tembus fiber optik

FE-50-V-V-R5

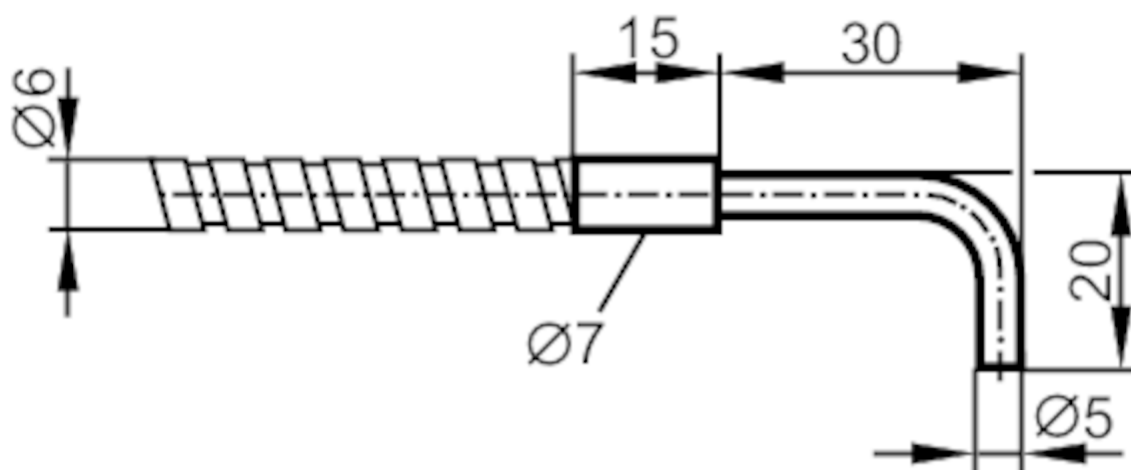

Aplikasi

Prinsip fungsi

Sensor sinar tembus

Zona pendeteksian

Jangkauan dengan tipe
amplifier fiber optik

OBF; ODF; OMF

OBF

Jangkauan fiber optik

[mm]

1000

ODF

Jangkauan fiber optik

[mm]

4

OMF

Jangkauan fiber optik

[mm]

800

Kondisi pengoperasian

Suhu sekitar

[°C]

-58...315

Data teknis

Berat

[g]

174

Versi kepala pendeteksian

bersiku

Diameter kepala
pendeteksian

[mm]

5

Panjang total

[mm]

900

Radius pembengkokan min.

[mm]

19

Susunan fiber





Sensor sinar tembus fiber optik

FE-50-V-V-R5

Material fiber	kaca
Material kepala fiber	baja tahan karat (1.4305/303)
Material selubung fiber	baja tahan karat (1.4305/303)
Keterangan	
Jumlah paket	1 buah