


Sensor refleksi difus fiber optik

FT-50-V-V-E4,7

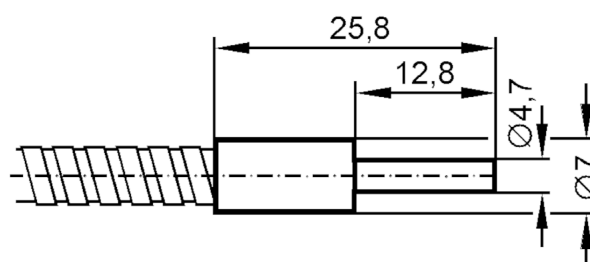

Aplikasi		
Prinsip fungsi		Sensor refleksi difus
Zona pendeteksian		
Jangkauan dengan tipe amplifier fiber optik		OBF; ODF; OMF
OBF		
Jangkauan fiber optik	[mm]	150
ODF		
Jangkauan fiber optik	[mm]	1
OMF		
Jangkauan fiber optik	[mm]	175
Kondisi pengoperasian		
Suhu sekitar	[°C]	-58...315
Data teknis		
Berat	[g]	112.5
Versi kepala pendeteksian		lurus
Diameter kepala pendeteksian	[mm]	4.7
Panjang total	[mm]	900
Susunan fiber		⓪
Material fiber		kaca
Material kepala fiber		baja tahan karat (1.4305/303)
Material selubung fiber		baja tahan karat (1.4305/303)
Keterangan		
Jumlah paket		1 buah