


Sensor sinar tembus fiber optik

FE-00-P-A-M4

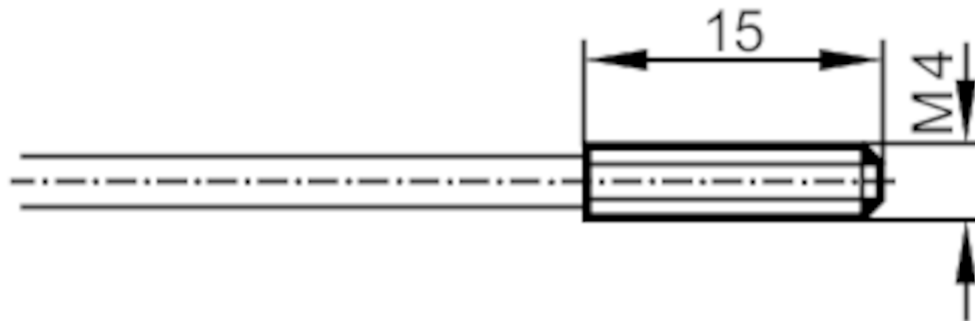

Aplikasi		
Prinsip fungsi		Sensor sinar tembus
Aplikasi		Radius pembengkokan kecil
Zona pendeteksian		
Jangkauan dengan tipe amplifier fiber optik		OCF; OKF; OOF; OUF
OCF (High Power)		
Jangkauan fiber optik	[mm]	790
OKF		
Jangkauan fiber optik	[mm]	120
OOF		
Jangkauan fiber optik	[mm]	400
OUF		
Jangkauan fiber optik	[mm]	120
Kondisi pengoperasian		
Suhu sekitar	[°C]	-20...80
Data teknis		
Berat	[g]	41
Versi kepala pendeteksian		lurus
Ulir kepala pendeteksian		M4

E20059



Sensor sinar tembus fiber optik

FE-00-P-A-M4

Panjang kepala pendeteksian [mm]	15
Panjang total [mm]	600
Radius pembengkokan min. [mm]	10
Susunan fiber	
Material	Adaptor: PPE
Material fiber	kaca
Material kepala fiber	aluminium
Material selubung fiber	PVC

Aksesori

Item dikirim	mur segi enam: 4 x M4
	washer pengunci bergerigi: 4
	mur bergerigi: 1 x M11

Keterangan

Jumlah paket	1 buah
--------------	--------