




Sensor sinar tembus fiber optik

FE-00-P-A-E2,5

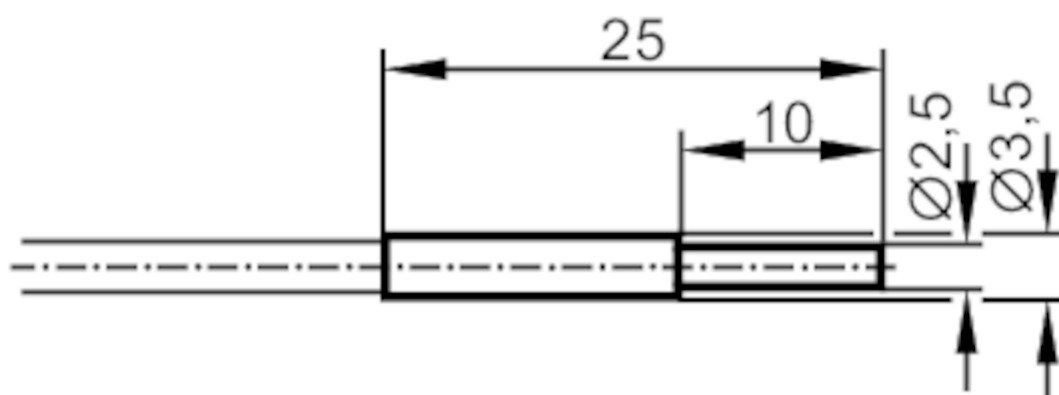

Aplikasi

Prinsip fungsi

Sensor sinar tembus

Aplikasi

Radius pembengkokan kecil

Zona pendeteksian

Jangkauan dengan tipe
amplifier fiber optik

OCF; OKF; OOF; OUF

OCF (High Power)

Jangkauan fiber optik

[mm]

1020

OKF

Jangkauan fiber optik

[mm]

120

OOF

Jangkauan fiber optik

[mm]

400

OUF

Jangkauan fiber optik

[mm]

120

Kondisi pengoperasian

Suhu sekitar

[°C]

-20...80

Data teknis

Berat

[g]

53.5

Versi kepala pendeteksian

lurus

Diameter kepala
pendeteksian

[mm]

2.5

E20060



Sensor sinar tembus fiber optik

FE-00-P-A-E2,5

Panjang kepala pendeteksian [mm]	10
Panjang total [mm]	600
Radius pembengkokan min. [mm]	10
Susunan fiber	
Material	Adaptor: PPE
Material fiber	kaca
Material kepala fiber	aluminium
Material selubung fiber	PVC
Aksesori	
Item dikirim	E20106
Keterangan	
Jumlah paket	1 buah