




Sensor sinar tembus fiber optik

FE-00-P-A-M4/2M

Produk tidak tersedia - entri arsip

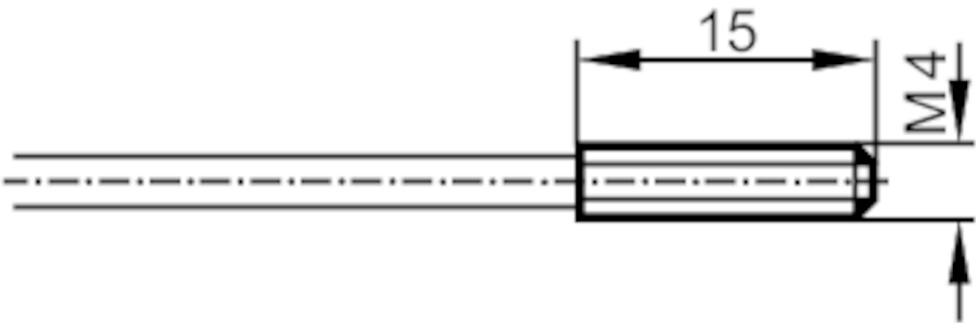

Aplikasi		
Prinsip fungsi		Sensor sinar tembus
Zona pendeteksian		
Jangkauan dengan tipe amplifier fiber optik		OKF; OUF
OKF		
Jangkauan fiber optik	[mm]	96
OUF		
Jangkauan fiber optik	[mm]	96
Kondisi pengoperasian		
Suhu sekitar	[°C]	-20...80
Data teknis		
Berat	[g]	0.063
Versi kepala pendeteksian		lurus
Ulir kepala pendeteksian		M4
Panjang kepala pendeteksian	[mm]	15
Panjang total	[mm]	2000
Radius pembengkokan min.	[mm]	10
Susunan fiber		

**Sensor sinar tembus fiber optik**

FE-00-P-A-M4/2M

Material	Adaptor: PPE
Material fiber	kaca
Material kepala fiber	aluminium
Material selubung fiber	PVC
Aksesori	
Item dikirim	mur segi enam: 4 x M4
	washer pengunci bergerigi: 4
	mur bergerigi: 1 x M11
Keterangan	
Jumlah paket	1 buah