


Sensor sinar tembus fiber optik

FE-00-P-A-R3

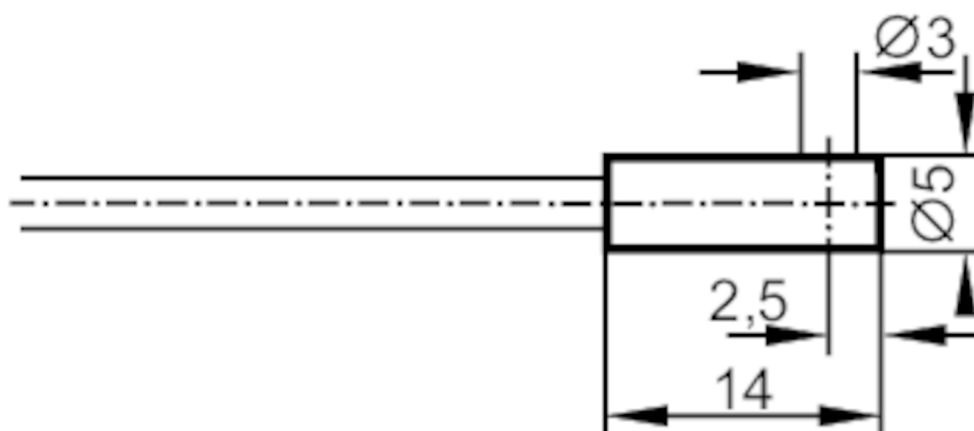

Aplikasi

Desain	defleksi 90° dari sinar cahaya
Prinsip fungsi	Sensor sinar tembus
Aplikasi	Untuk digunakan di lingkungan industri

Zona pendeteksian

Jangkauan dengan tipe amplifier fiber optik	OKF; OUF; OOF
---	---------------

OKF

Jangkauan fiber optik [mm]	120
----------------------------	-----

OOF

Jangkauan fiber optik [mm]	400
----------------------------	-----

OUF

Jangkauan fiber optik [mm]	120
----------------------------	-----

Kondisi pengoperasian

Suhu sekitar [°C]	-20...80
-------------------	----------

Data teknis

Berat [g]	54.5
Versi kepala pendeteksian	bersiku
Diameter kepala pendeteksian [mm]	5
Panjang total [mm]	600

E20228



Sensor sinar tembus fiber optik

FE-00-P-A-R3

Radius pembengkokan min. [mm]	20
Susunan fiber	
Material fiber	kaca
Material kepala fiber	aluminium
Material selubung fiber	PVC
Aksesori	
Item dikirim	E20104
Keterangan	
Jumlah paket	1 buah