


E20300



Sensor refleksi difus fiber optik

FT-00-P-V-E1/0,25M

Produk tidak tersedia - entri arsip

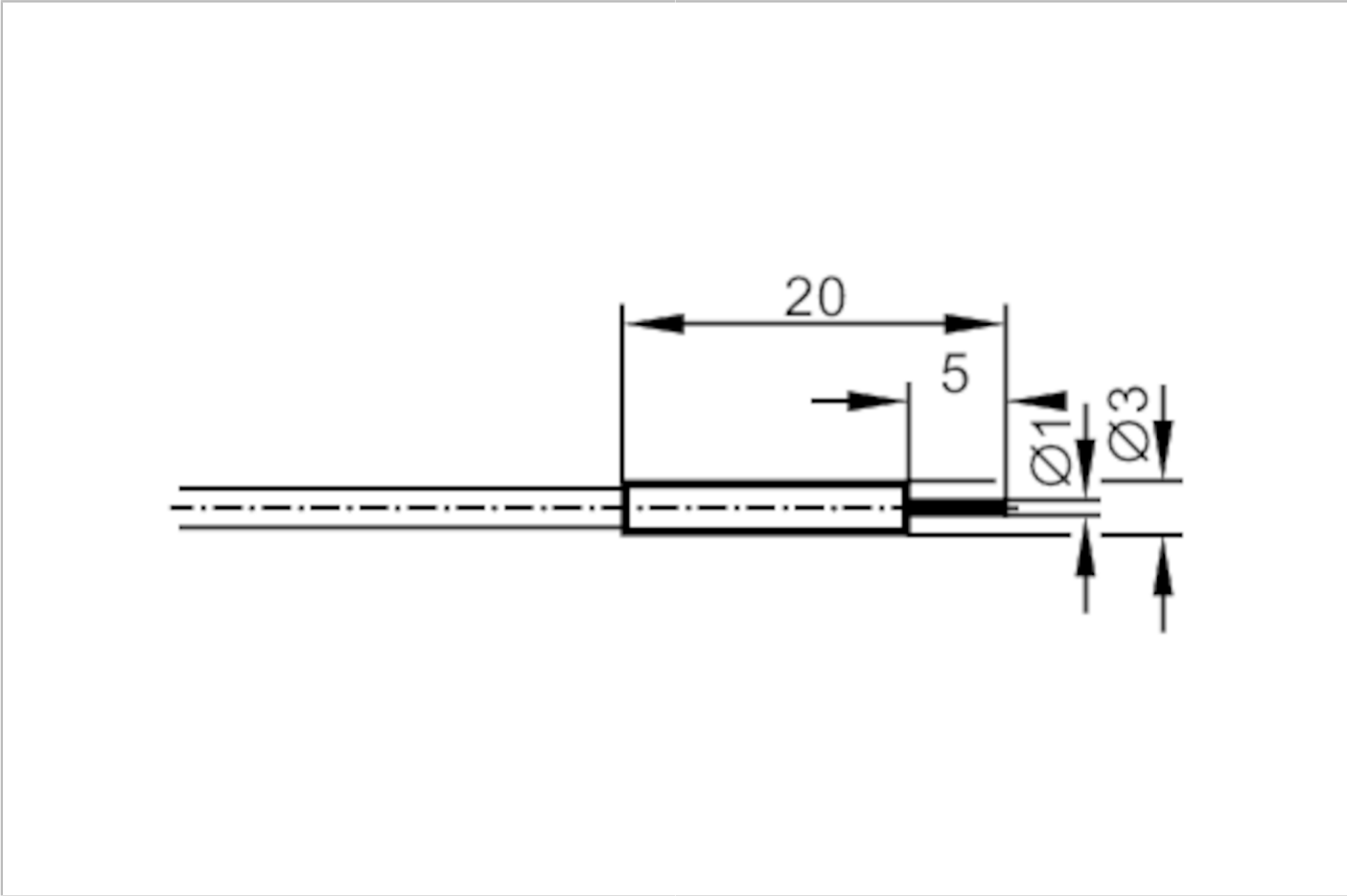

Aplikasi		
Prinsip fungsi		Sensor sinar tembus
Zona pendeteksian		
Jangkauan dengan tipe amplifier fiber optik		OKF; OUF
OKF		
Jangkauan fiber optik	[mm]	50
OUF		
Jangkauan fiber optik	[mm]	50
Kondisi pengoperasian		
Suhu sekitar	[°C]	-20...80
Data teknis		
Versi kepala pendeteksian		lurus
Diameter kepala pendeteksian	[mm]	1
Panjang kepala pendeteksian	[mm]	5
Panjang total	[mm]	250
Radius pembengkokan min.	[mm]	10
Material		Adaptor: PPE

E20300



Sensor refleksi difus fiber optik

FT-00-P-V-E1/0,25M

Material fiber	kaca
Material kepala fiber	baja tahan karat (1.4305/303)
Material selubung fiber	PVC
Keterangan	
Jumlah paket	1 buah