


## Kabel koneksi Ethernet

VSTGN040ZDS0005L04STGN040ZDS

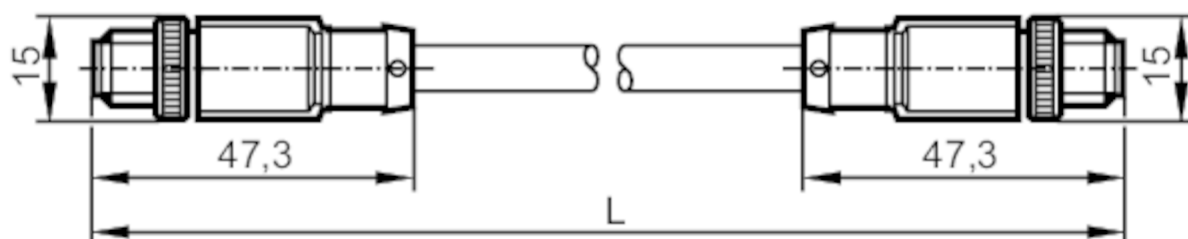

## Aplikasi

Fitur khusus

Kontak berlapis emas; Kabel berpelindung

Desain

Kabel Ethernet, Dengan kode D

## Data kelistrikan

Tegangan pengoperasian

[V]

&lt; 50 AC / &lt; 60 DC

Kelas perlindungan

III

Total beban arus maks.

[A]

4

## Kondisi pengoperasian

Suhu sekitar

[°C]

-20...90

Perlindungan

IP 67

## Data teknis

Berat

[g]

369.2

Dimensi

[mm]

15 x 15 x 47.3

Material

TPU

Material bodi detakan

TPU

Material mur

seng tuang, berlapis nikel

## Keterangan

Jumlah paket

1 buah

## Kabel koneksi Ethernet

VSTGN040ZDS0005L04STGN040ZDS

### Koneksi listrik - colokan


Konektor: 1 x M12, lurus; pengkodean: D; Bodi cetakan: TPU; Penguncian: seng tuang, berlapis nikel; Kontak: dilapisi emas; Kabel koneksi berpelindung: pelindung terhubung



### Koneksi listrik

Kabel: 5 m, PVC, hijau, berpelindung; 4 x 0.34 mm<sup>2</sup>

### Koneksi

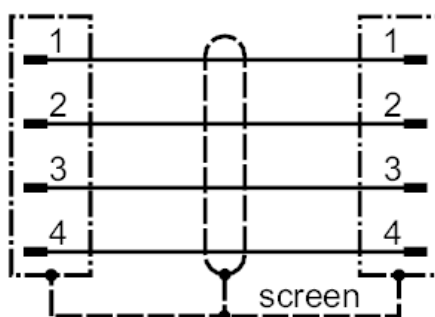

### Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: D; Bodi cetakan: TPU; Penguncian: seng tuang, berlapis nikel; Kontak: dilapisi emas; Kabel koneksi berpelindung: pelindung terhubung

