




Sensor refleksi difus fiber optik

FT-11-EPV-O6/FHx1/2m

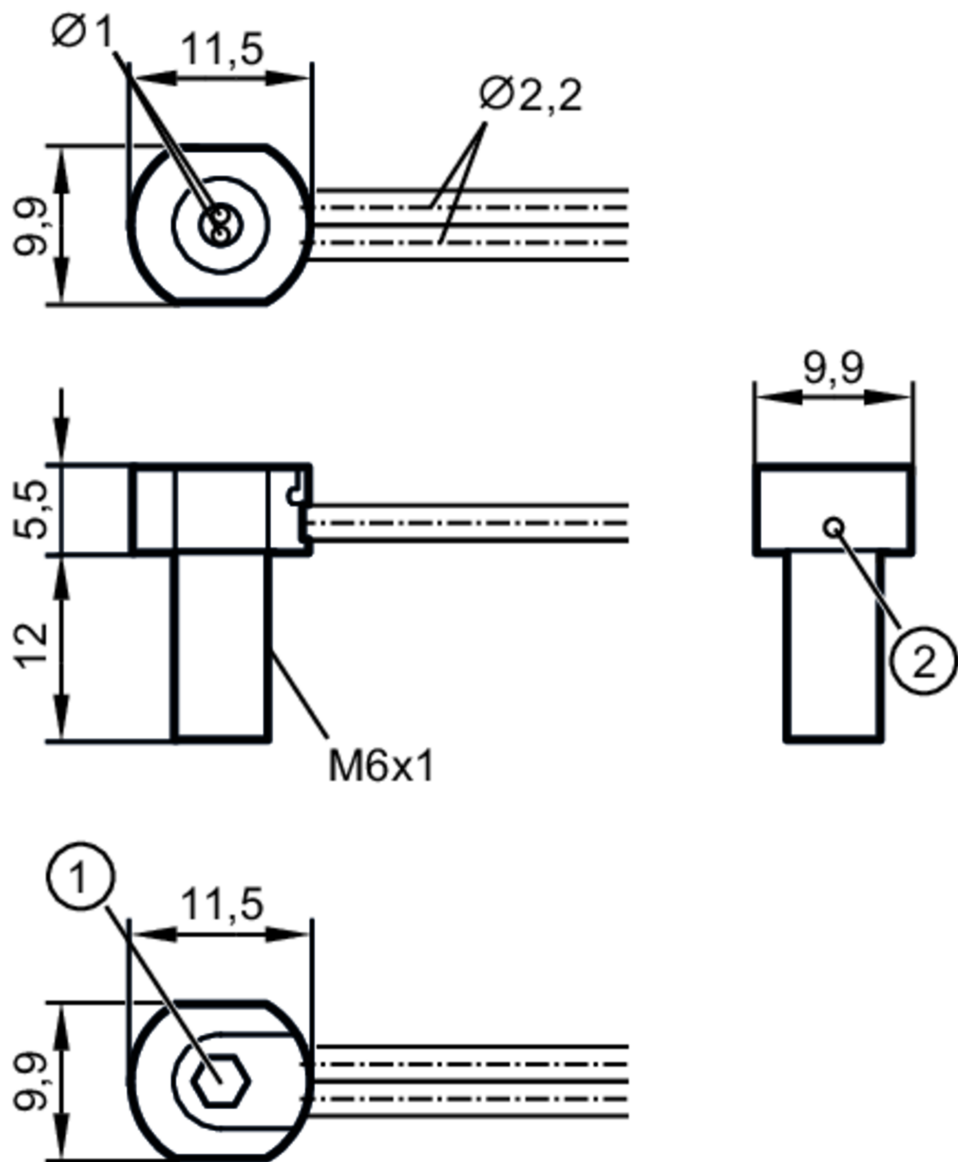

- 1 soket segi enam 3 mm
2 lubang bor untuk alat pemasangan

Aplikasi		
Prinsip fungsi	Sensor refleksi difus	
Aplikasi	Untuk digunakan di lingkungan industri	
Zona pendeteksian		
Jangkauan dengan tipe amplifier fiber optik	OBF; OO50; OCF	
OBF		
Jangkauan fiber optik	[mm]	70
OO50		
Jangkauan fiber optik	[mm]	150

E21316



Sensor refleksi difus fiber optik

FT-11-EPV-O6/FHx1/2m

OCF (High Power)		
Jangkauan fiber optik	[mm]	490
Kondisi pengoperasian		
Suhu sekitar	[°C]	-40...70
Data teknis		
Berat	[g]	50
Versi kepala pendeteksian		bersiku
Ulir kepala pendeteksian		M6
Panjang total	[mm]	2000
Radius pembengkokan min.	[mm]	2
Susunan fiber		⦿
Diameter core	[mm]	1
Material fiber		PMMA
Material kepala fiber		baja tahan karat (1.4305/303)
Material selubung fiber		PE
Aksesori		
Item dikirim		mur segi enam: 2 x M6
		washer pengunci bergerigi: 2
Aksesori (opsional)		Pemotong untuk fiber optik:, E20600
Keterangan		
Jumlah paket		1 buah