




Sensor sinar tembus fiber optik

FE-11-EPV-O6/F1x1/2m

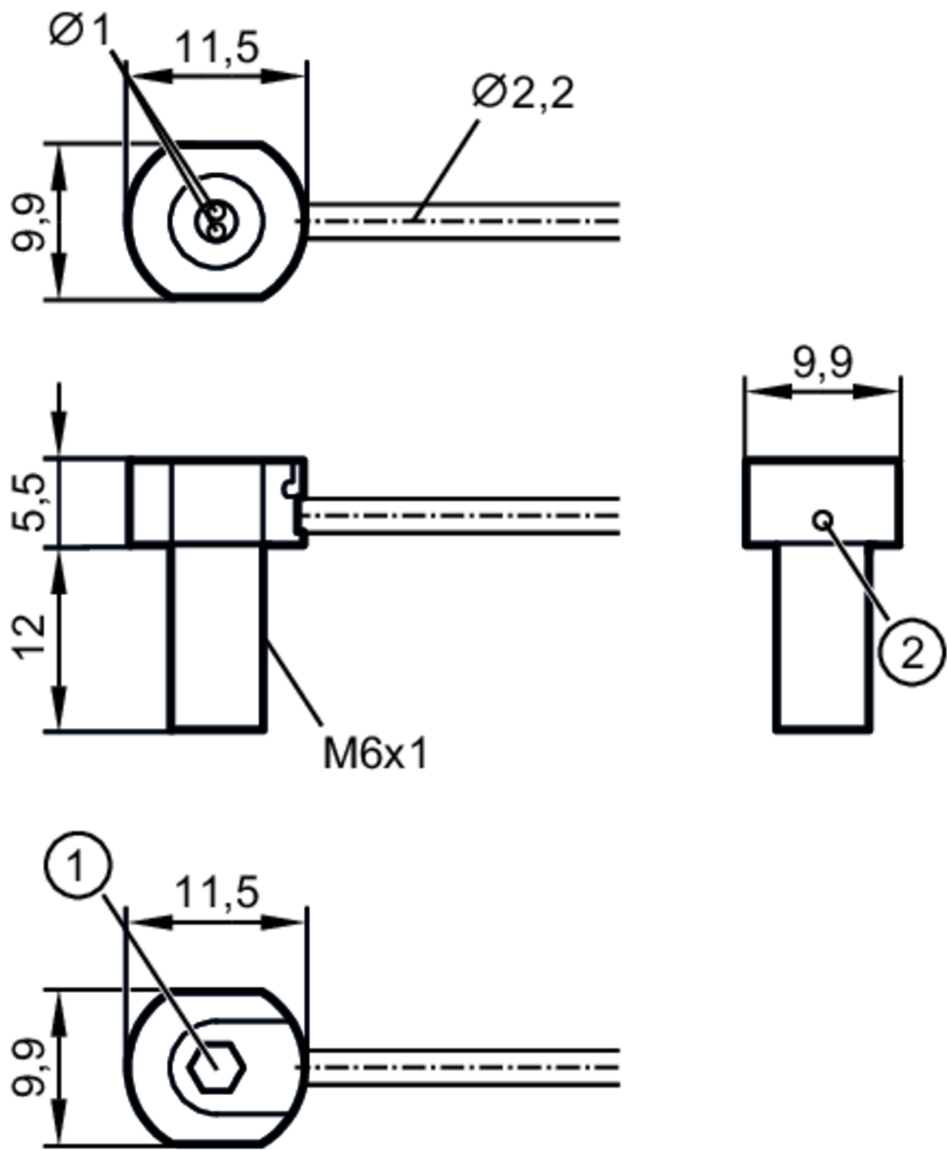

- 1 soket segi enam 3 mm
2 lubang bor untuk alat pemasangan

Aplikasi

Prinsip fungsi

Sensor sinar tembus

Aplikasi

Untuk digunakan di lingkungan industri

Zona pendeteksian

Jangkauan dengan tipe
amplifier fiber optik

OBF; OO50; OCF

OBF

Jangkauan fiber optik

[mm]

210

OO50

Jangkauan fiber optik

[mm]

600



Sensor sinar tembus fiber optik

FE-11-EPV-O6/F1x1/2m

OCF (High Power)		
Jangkauan fiber optik	[mm]	2320
Kondisi pengoperasian		
Suhu sekitar	[°C]	-40...70
Data teknis		
Berat	[g]	56.4
Versi kepala pendeteksian		bersiku
Ulir kepala pendeteksian		M6
Panjang total	[mm]	2000
Radius pembengkokan min.	[mm]	2
Susunan fiber		●
Diameter core	[mm]	1
Material fiber		PMMA
Material kepala fiber		baja tahan karat (1.4305/303)
Material selubung fiber		PE
Aksesori		
Item dikirim		mur segi enam: 4 x M6
		washer pengunci bergerigi: 4
Aksesori (opsional)		Pemotong untuk fiber optik:, E20600
Keterangan		
Jumlah paket		1 buah