


E2M235



Video Switcher

VIDEO SWITCHER/3 PORT

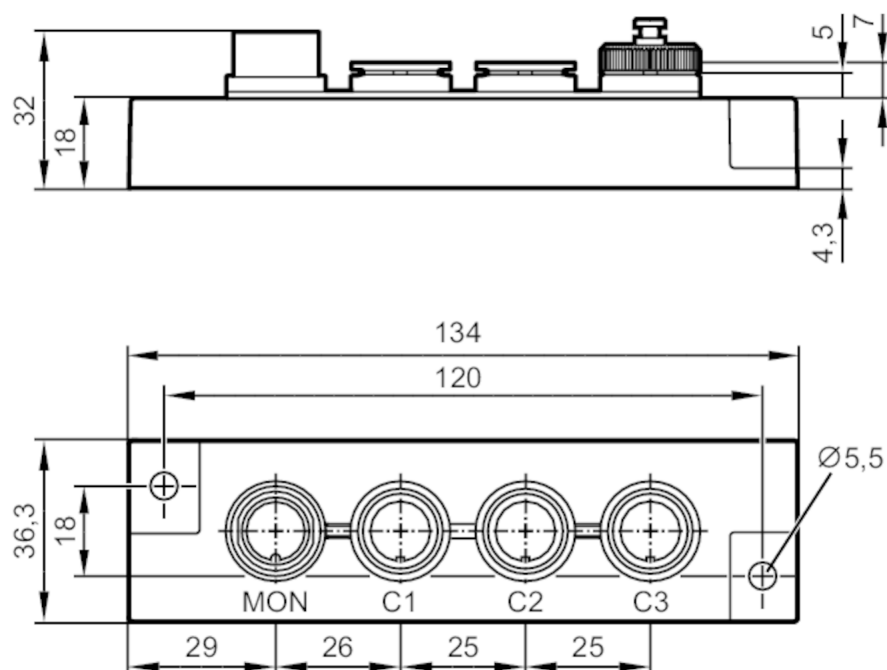

Data kelistrikan

Tegangan pengoperasian [V]	12 DC; ($\pm 1,5V$)
Pelindung tegangan berlebih	ya

Kondisi pengoperasian

Suhu sekitar [°C]	-40...85
Suhu penyimpanan [°C]	-40...125
Kelembapan penyimpanan [%]	< 75; (kelembapan relatif)
Lama penyimpanan [MON]	24
Perlindungan	IP 67

Data teknis

Berat [g]	149
Material	casing: ABS hitam

Aksesori

Item dikirim	Tutup pelindung
--------------	-----------------

Keterangan

Jumlah paket	1 buah
--------------	--------

 


Video Switcher

VIDEO SWITCHER/3 PORT

Koneksi listrik - colokan

Konektor: M16; pengkodean: A



MON

1	core kabel coax sinyal video
2	layar coax GND video
3	tidak digunakan
4	tidak digunakan

Koneksi listrik - soket

Konektor: M16; pengkodean: A



C1...3

1	core kabel coax sinyal video
2	layar coax GND video
3	U+
4	0 V