


E30406



Konverter tegangan

VOLTAGE CONVERTER

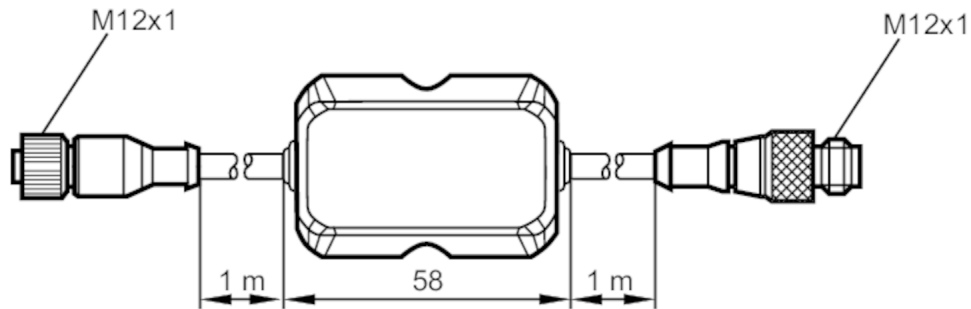

Data kelistrikan

Tegangan nominal DC	[V]	9...27
Konsumsi arus	[mA]	< 500
Kelas perlindungan		III
Pelindung polaritas terbalik		ya

Output

Pelindung hubung singkat	ya
--------------------------	----

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...70
Perlindungan		IP 40

Pengujian/persetujuan

EME	EN 61000-4-2 ESD	4 kV CD / 15 kV AD
	EN 61000-4-3 HF dipancarkan	30 V/m (80...1000 MHz)
	EN 61000-4-4 Burst	2 kV klem koneksi
	EN 61000-4-6 HF dihantarkan	10 V (0,15...80 MHz)

Data teknis

Berat	[g]	151
Material		PBT-GF20
Material penyegel		FKM

Keterangan

Jumlah paket	1 buah
--------------	--------

Koneksi listrik - soket

Kabel: 1 m, PUR

Konektor: 1 x M12; Bodi cetakan: TPU, oranye; Penguncian: kuningan, berlapis nikel; Segel: FKM

E30406




Konverter tegangan

VOLTAGE CONVERTER

Koneksi listrik

Koneksi

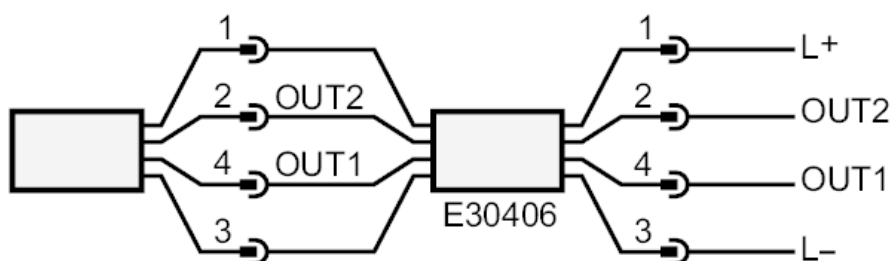

Koneksi listrik - colokan

Kabel: 1 m, PUR

Konektor: 1 x M12; Bodi cetakan: TPU, oranye; Penguncian: kuningan, berlapis nikel; Segel: FKM