


E30425



Tombol adaptasi untuk sensor tekanan

TEACH BUTTON

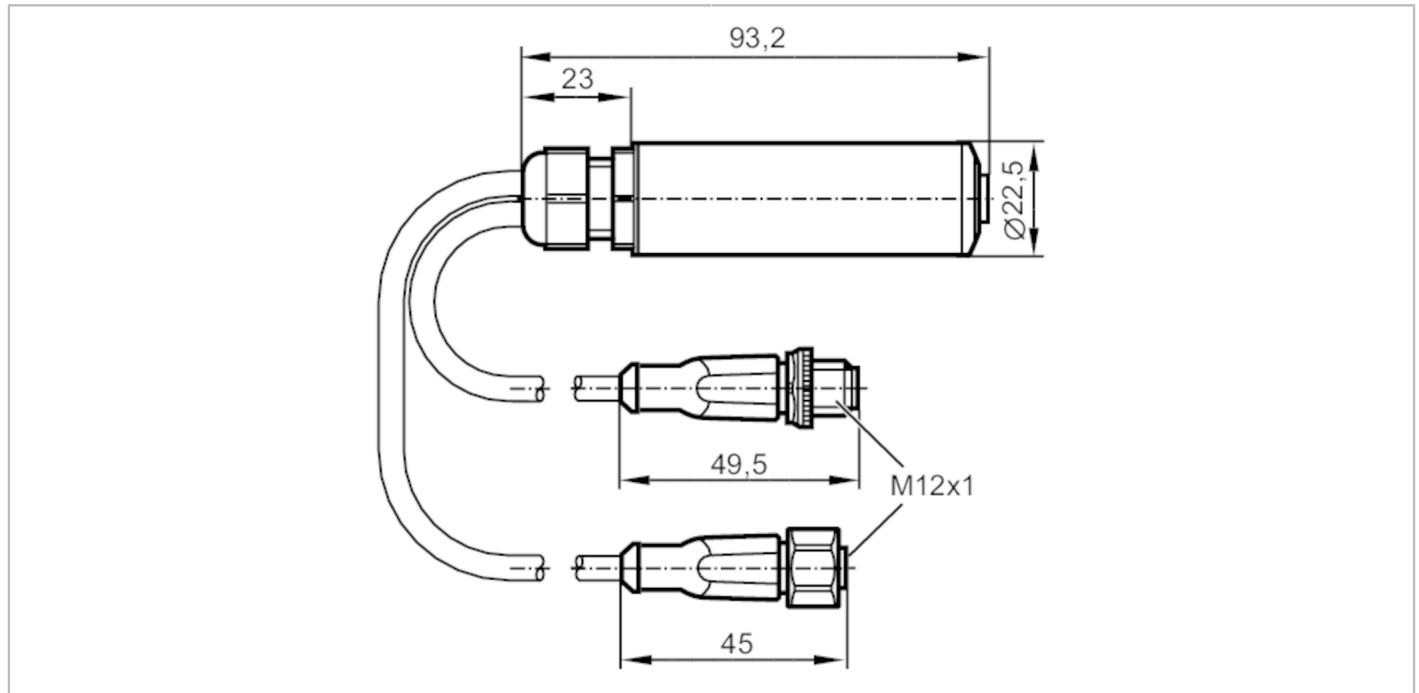

Aplikasi		
Desain		untuk sensor PM1xxx
Data kelistrikan		
Tegangan pengoperasian	[V]	20...30 DC
Output		
Beban maks.	[Ω]	(U _b - 14 V) / 21.5 mA
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...60
Perlindungan		IP 65
Pengujian/persetujuan		
MTTF	[ANN]	2927
Data teknis		
Berat	[g]	227
Material		baja tahan karat (1.4404 / 316L); PA; FFKM; PBT
Keterangan		
Keterangan		Jika tombol adaptasi terhubung, komunikasi IO-Link tidak dimungkinkan.
Jumlah paket		1 buah




Tombol adaptasi untuk sensor tekanan

TEACH BUTTON

Koneksi listrik

Kabel: 0.9 m, PUR; Panjang kabel maksimal: 30 m; antara sensor dan tombol adaptasi

Koneksi

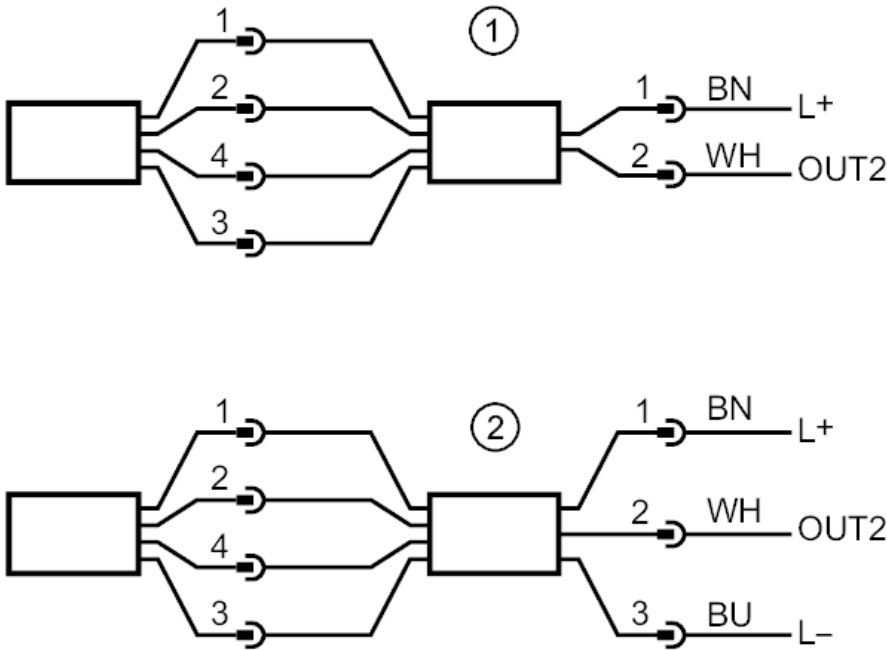

- | | |
|------|-------------------------------|
| 1 | pengoperasian 2 kawat |
| 2 | pengoperasian 3 kawat |
| OUT2 | 4...20 mA |
| | warna sesuai DIN EN 60947-5-2 |