

E30080




Suplai daya plug-in

POWER SUPPLY 24V IP40/IP67

Produk tidak tersedia - entri arsip

Produk alternatif: E80120
Ketika memilih produk dan aksesoris alternatif, perhatikan bahwa data teknis mungkin berbeda!

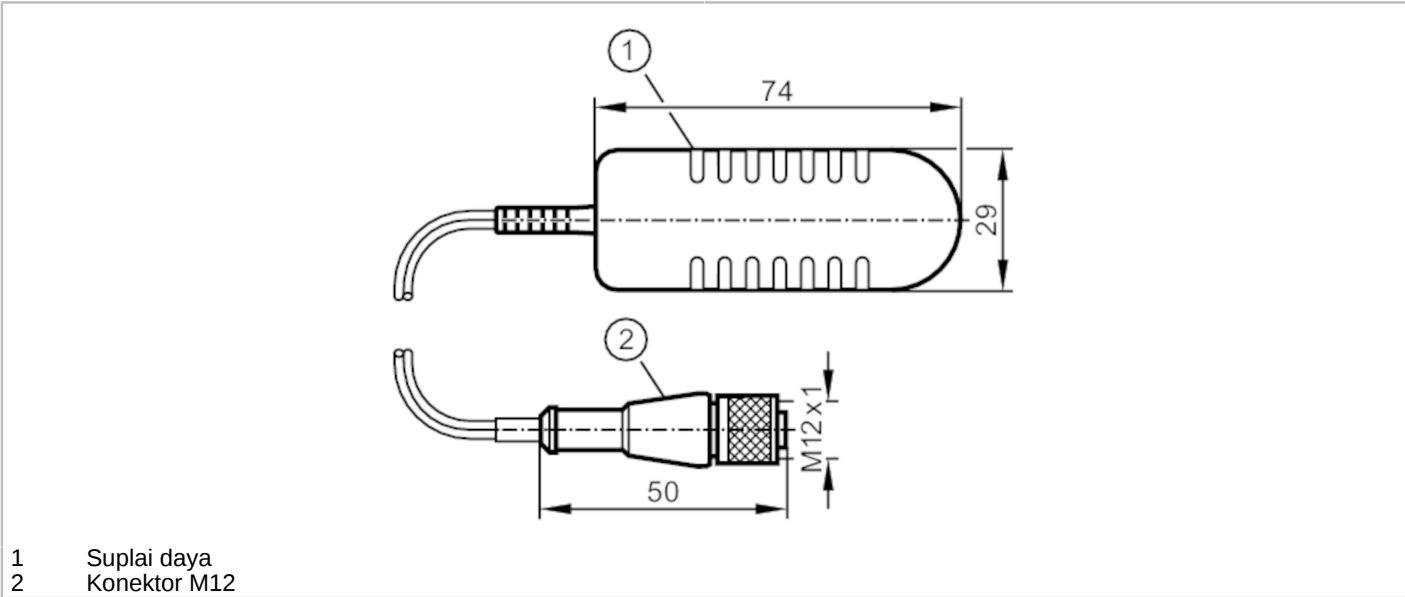

Data kelistrikan		
Frekuensi nominal AC	[Hz]	50...60
Rentang tegangan input AC	[V]	100...240
Tegangan output DC	[V]	24
Arus input (tegangan nominal 230 V AC / 50 Hz)	[A]	0.2
Output		
Arus output, total	[A]	0.33
Kondisi pengoperasian		
Perlindungan	IP 40; (Konektor M12: IP 67)	
Data teknis		
Berat	[g]	135
Material	PPE	
Keterangan		
Jumlah paket	1 buah	
Koneksi listrik		
Kabel: 2 m; 2 x 0.5 mm²		
Konektor: 1 x M12		