


Sensor sinar tembus fiber optik

FIBRE OPTIC 2M

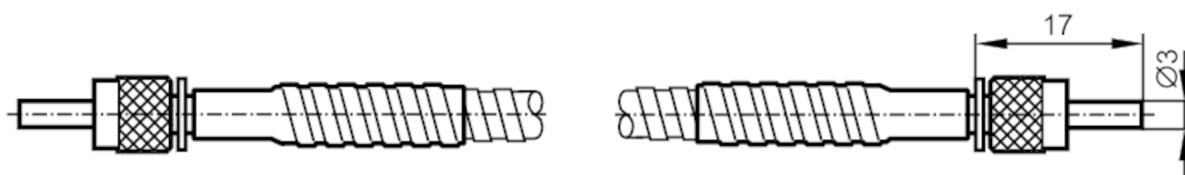

Aplikasi

Desain	koneksi ke sensor suhu inframerah TWxx11
--------	--

Kondisi pengoperasian

Suhu sekitar	[°C]	-40...250
--------------	------	-----------

Data teknis

Berat	[g]	162.8
Koneksi fiber optik		¼"-36UNS-2A
Versi kepala pendeteksian		lurus
Panjang total	[mm]	2000
Radius pembengkokan min.	[mm]	120
Susunan fiber		●
Material fiber		quartz / quartz
Material kepala fiber		CuNiZn
Material selubung fiber		baja tahan karat

Keterangan

Jumlah paket	1 buah
--------------	--------