




Kabel koneksi dengan soket


ADOGH050MSS0010E05

Produk tidak tersedia - entri arsip

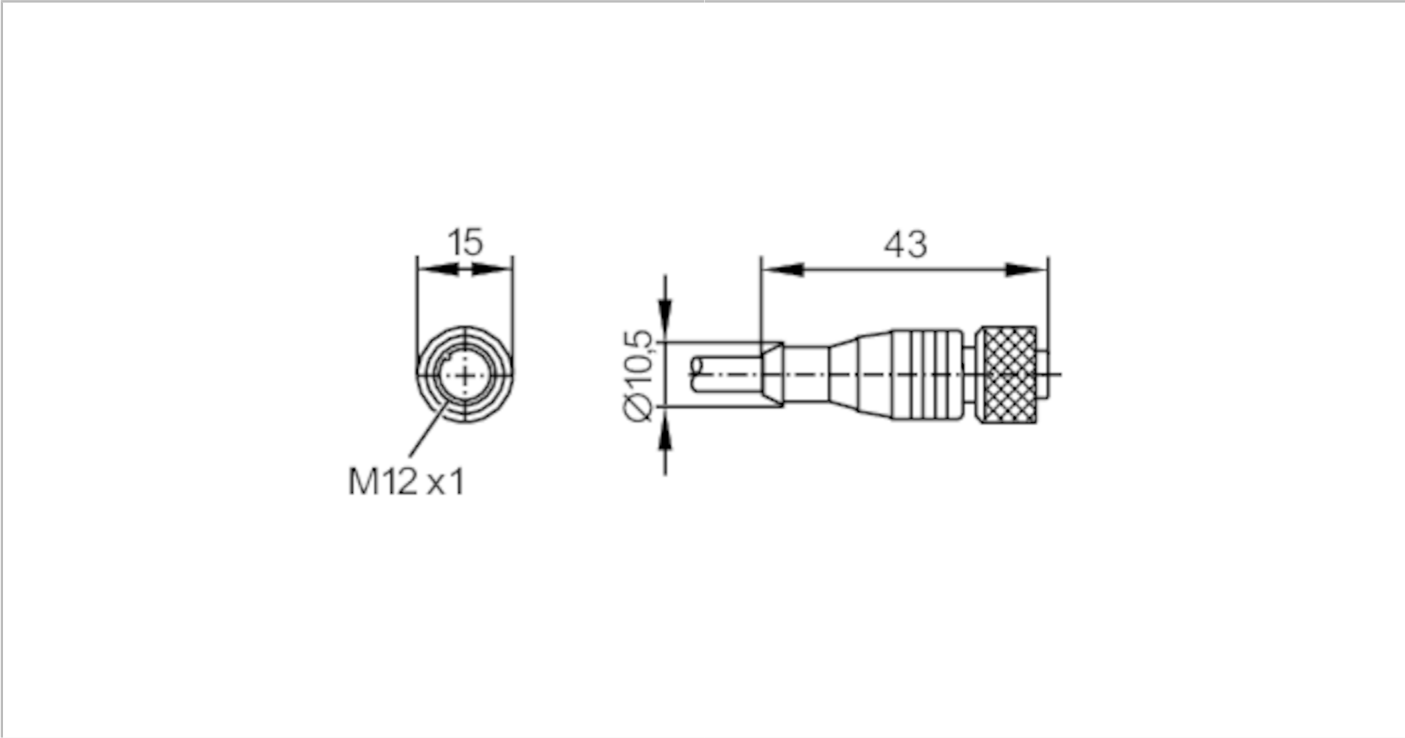

Data kelistrikan		
Tegangan pengoperasian	[V]	< 30 AC / < 36 DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67
Data teknis		
Dimensi	[mm]	15 x 15 x 43
Material		TPU
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
Kabel: 10 m, PVC, oranye; 5 x 0.34 mm² (42 x Ø 0.1 mm)		
Koneksi listrik - soket		

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

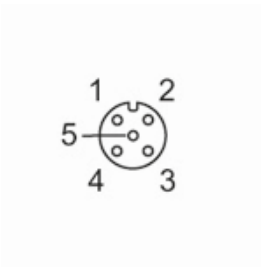




Kabel koneksi dengan soket

ADOGH050MSS0010E05

Koneksi

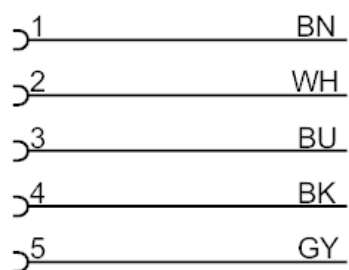

	Warna core :
BK =	hitam
BN =	coklat
BU =	biru
GY =	abu-abu
WH =	putih