


E43332



Kabel koneksi

CABLE CAN ADAPTER

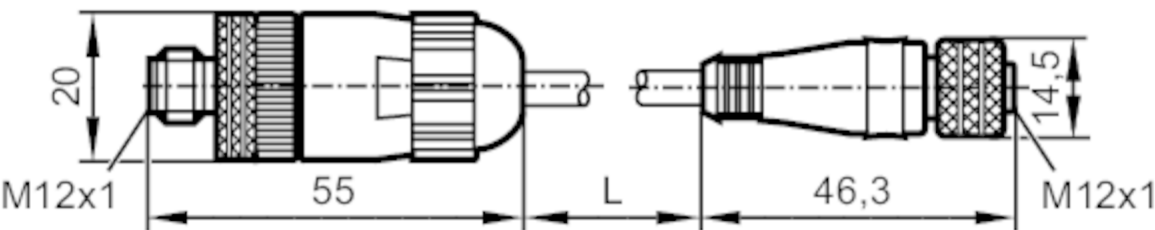

L: 0.15 m

Aplikasi		
Fitur khusus		Kontak berlapis emas
Desain		kabel adaptor CAN
Data kelistrikan		
Tegangan pengoperasian	[V]	< 30 AC / < 36 DC
Total beban arus maks.	[A]	4
Kondisi pengoperasian		
Suhu sekitar	[°C]	-30...80
Perlindungan		IP 68
Data teknis		
Berat	[g]	48.8
Dimensi	[mm]	20 x 20 x 55
Material		PUR
Material bodi detakan		PUR
Material mur		kuningan, berlapis nikel
Keterangan		
Jumlah paket		1 buah

Kabel koneksi

CABLE CAN ADAPTER

Koneksi listrik - colokan


Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas



Koneksi listrik

Kabel: 0.15 m, PUR / PVC, hitam, Ø 6.8 mm; 4 x 0.25 mm²

Koneksi

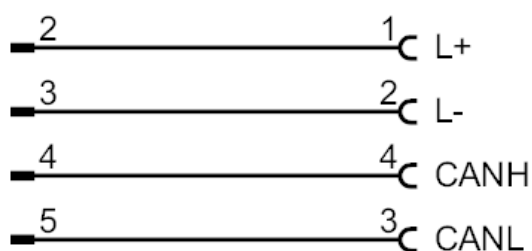

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas

