


Colokan berkabel

SSTGK120--LFKSG

Produk tidak tersedia - entri arsip

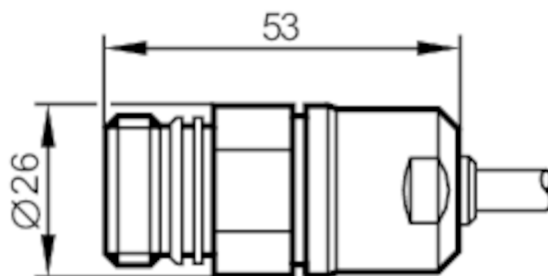

Data kelistrikan

Tegangan pengoperasian	[V]	4.5...30 DC
------------------------	-----	-------------

Kondisi pengoperasian

Suhu sekitar	[°C]	-40...125
--------------	------	-----------

Perlindungan		IP 67
--------------	--	-------

Data teknis

Berat	[g]	53.2
-------	-----	------

Dimensi	[mm]	26 x 26 x 53
---------	------	--------------

Material		kuningan dalam selubung plastik; PA 6.6 hitam
----------	--	---

Material bodi detakan		kuningan / PA 6.6, dalam selubung plastik
-----------------------	--	---

Keterangan


Jumlah paket		1 buah
--------------	--	--------

Koneksi listrik

penyolderan: ...1 mm²

Koneksi listrik - colokan

Konektor: 1 x M23, lurus; Bodi cetakan: kuningan / PA 6.6, dalam selubung plastik

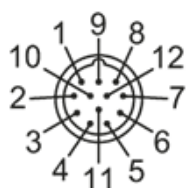



Colokan berkabel

SSTGK120--LFKSG

Koneksi

