


E60174



Soket berkabel

SDOGJ120MSLFKPG

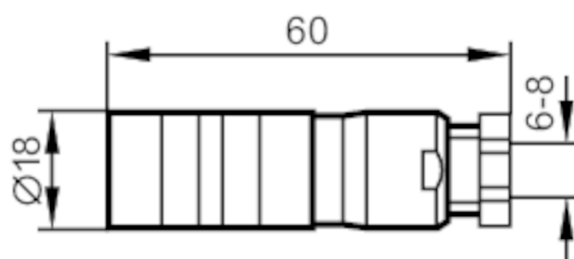

Data kelistrikan

Tegangan pengoperasian	[V]	4.5...30 DC
------------------------	-----	-------------

Kondisi pengoperasian

Suhu sekitar	[°C]	-40...85
Perlindungan		IP 67

Data teknis

Berat	[g]	55.3
Dimensi	[mm]	18 x 18 x 60
Material		kuningan berlapis nikel
Material bodi detakan		kuningan, berlapis nikel
Material mur		kuningan, berlapis nikel

Keterangan

Jumlah paket		1 buah
--------------	--	--------

E60174



Soket berkabel

SDOGJ120MSLFPKG

Koneksi listrik

penyolderan: ...0.25 mm²; Selubung kabel: Ø 6...8 mm

Koneksi listrik - soket

Konektor: 1 x M18, lurus; Bodi cetakan: kuningan, berlapis nikel; Penguncian: kuningan, berlapis nikel



Koneksi

