




Konektor perpindahan isolasi kabel pipih AS-Interface

FC Splitter AS-i / AUX 1 m M12 UL

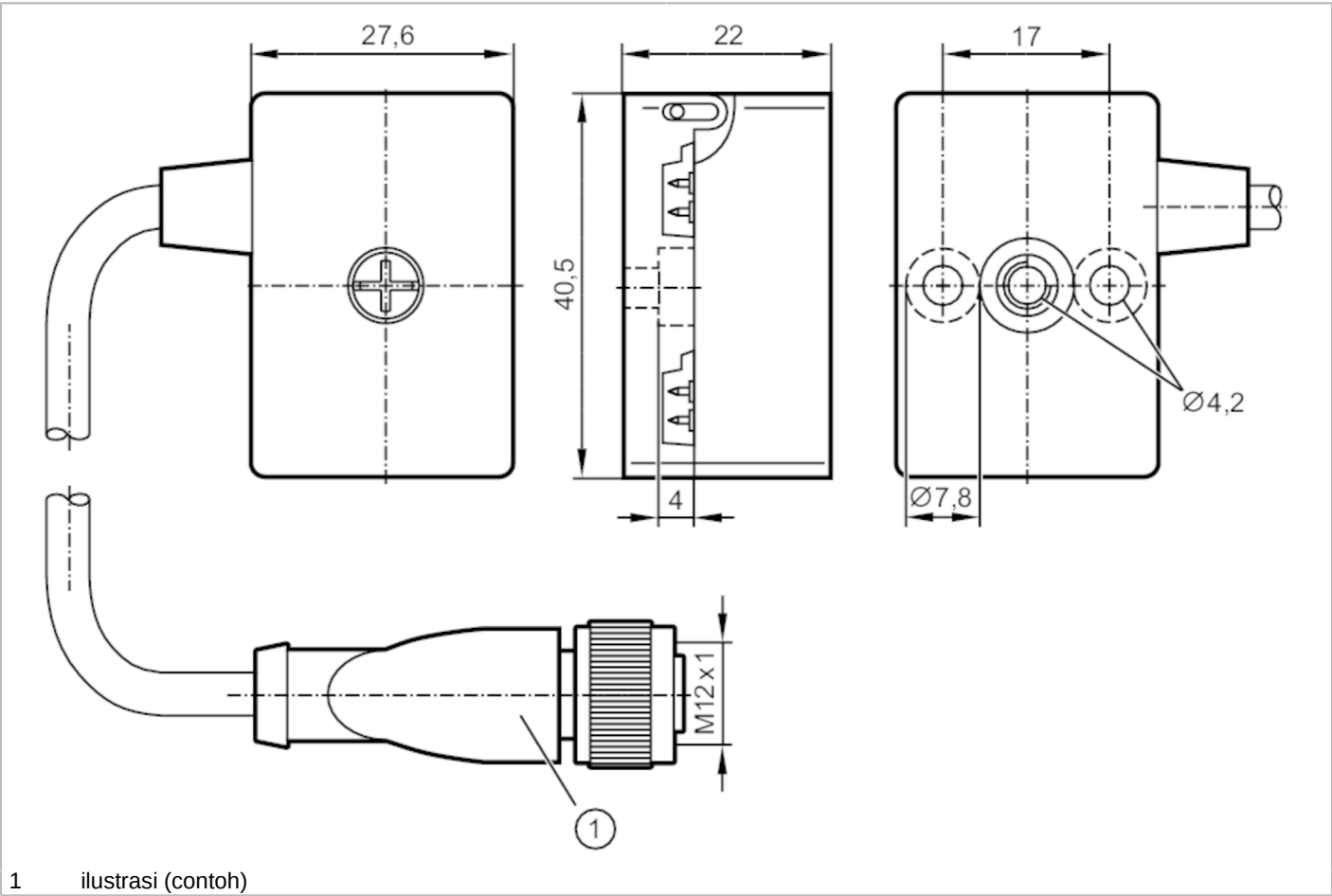

Aplikasi	
Aplikasi	distribusi tegangan AS-i dan suplai 24 V eksternal ke soket M12
Data kelistrikan	
Kelas perlindungan	III
Beban arus maks. per modul/ slot [A]	4
Output	
Desain kelistrikan	AS-i; (24V)
Kondisi pengoperasian	
Suhu sekitar [°C]	-25...75
Perlindungan	IP 67
Data teknis	
Berat [g]	89
Material	casing: PBT / PC
Torsi pengencangan [Nm]	1.65
Aksesori	
Aksesori (opsional)	segel ujung kabel pipih.; E70413
	selang penyusut.; E70113



Konektor perpindahan isolasi kabel pipih AS-Interface

FC Splitter AS-i / AUX 1 m M12 UL

Keterangan	
Keterangan	Kabel pipih tidak boleh berakhir di splitter. Gunakan segel kabel pipih atau tutup heat-shrink untuk penyegelan.
Jumlah paket	1 buah
Koneksi listrik	
Kabel: 1 m, PUR, Ø 4.3 mm; 4 x 0.34 mm ²	
Konektor: M12; pengkodean: A; Bodi cetakan: PUR; Torsi pengencangan: ...1.65 Nm	
1	AS-i +
2	AUX -
3	AS-i -
4	AUX +