




Konektor perpindahan isolasi kabel pipih AS-Interface

FC Splitter AS-i 0.6 m M12 UL

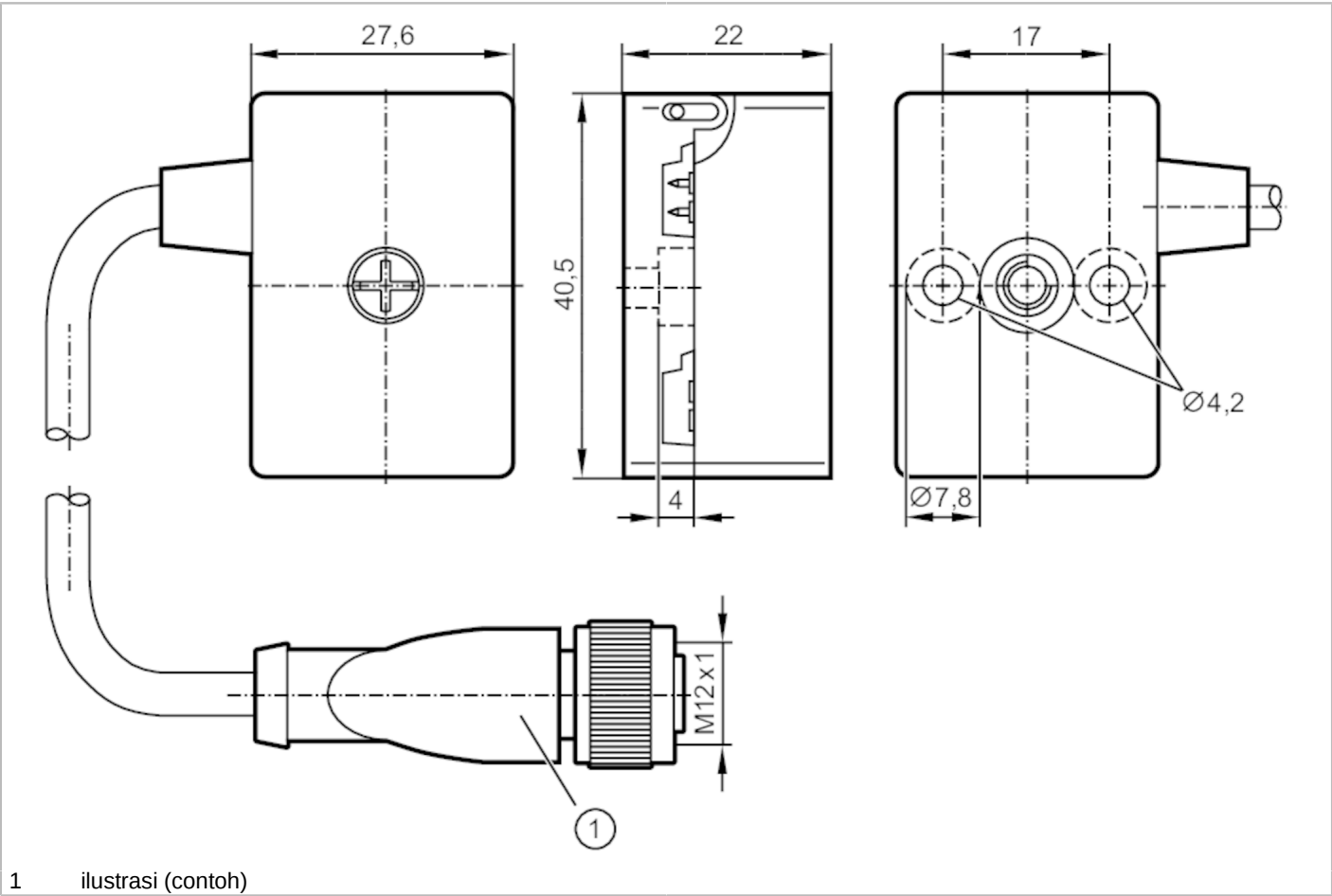

Aplikasi		
Aplikasi		distribusi tegangan AS-i ke soket M12
Data kelistrikan		
Kelas perlindungan		III
Beban arus maks. per modul/ slot	[A]	4
Output		
Desain kelistrikan		AS-i
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...75
Perlindungan		IP 67
Data teknis		
Berat	[g]	83.1
Material		casing: PBT / PC
Torsi pengencangan	[Nm]	1.65
Aksesori		
Aksesori (opsional)		segel ujung kabel pipih:, E70413
		selang penyusut:, E70113



Konektor perpindahan isolasi kabel pipih AS-Interface


FC Splitter AS-i 0.6 m M12 UL

Keterangan	
Keterangan	Kabel pipih tidak boleh berakhir di splitter. Gunakan segel kabel pipih atau tutup heat-shrink untuk penyegelan.
Jumlah paket	1 buah


Koneksi listrik

Kabel: 0.6 m, PUR, Ø 4.3 mm; 2 x 0.34 mm²

Konektor: M12; pengkodean: A; Bodi cetakan: PUR

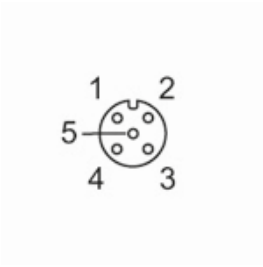

Koneksi

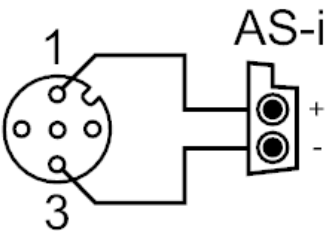

1	AS-i +
3	AS-i -