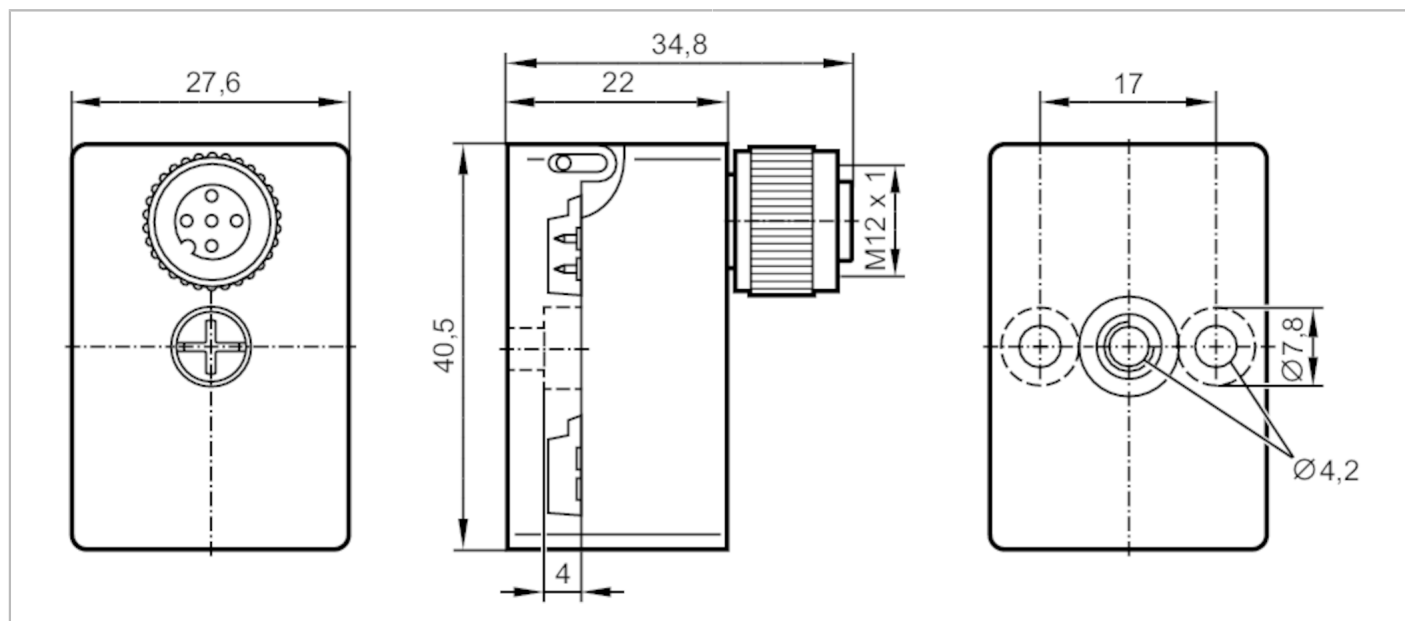


Konektor perpindahan isolasi kabel pipih AS-Interface

FC Splitter AS-i / AUX M12 UL



Data kelistrikan

Kelas perlindungan	III
Beban arus maks. per modul/ slot [A]	4

Output

Desain kelistrikan	AS-i
--------------------	------

Kondisi pengoperasian

Suhu sekitar [°C]	-25...75
Perlindungan	IP 67

Data teknis

Berat [g]	60.5
Material	casing: PBT / PC; sekrup: baja tahan karat (1.4305/303)
Torsi pengencangan [Nm]	< 1.65

Aksesori

Aksesori (opsional)	segel ujung kabel pipih:, E70413
	selang penyusut:, E70113

Keterangan

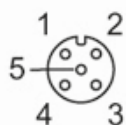
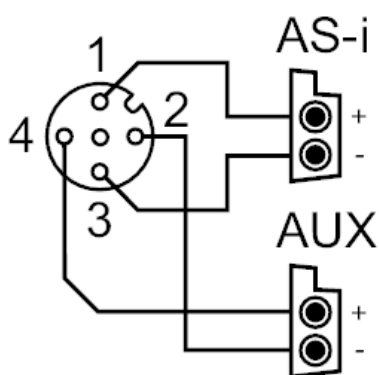
Keterangan	Kabel pipih sebaiknya tidak berakhir di splitter. Gunakan segel kabel pipih atau tutup heat-shrink untuk penyegelan.
Jumlah paket	1 buah

Konektor perpindahan isolasi kabel pipih AS-Interface

FC Splitter AS-i / AUX M12 UL

Koneksi listrik

Konektor: M12; pengkodean: A; Bodi cetakan: PUR

**Koneksi**

1	AS-i +
2	AUX -
3	AS-i -
4	AUX +