


Distributor daya AS-Interface

QUAD M12 AS-i/24V 4A

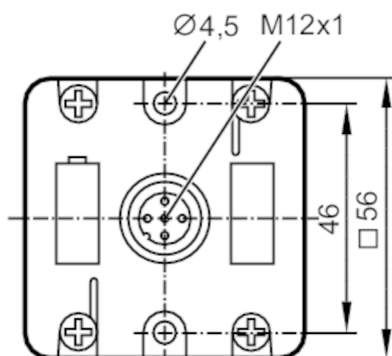

Aplikasi

Desain

AS-i / 24 V

Data kelistrikan

Tegangan pengoperasian	[V]	26.5...31.6 DC
Total beban arus maks.	[A]	2
Suplai tegangan tambahan	[V]	24 DC

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...75
Perlindungan		IP 65

Data teknis


Berat	[g]	95.5
Material		PA 6.6; soket: baja tahan karat (1.4404 / 316L); sekrup: baja tahan karat (1.4404 / 316L); mur: baja tahan karat (1.4404 / 316L); O-ring: NBR; segel kabel pipih: NBR

Keterangan

Jumlah paket		1 buah
--------------	--	--------

Koneksi listrik

Konektor: M12; pengkodean: A

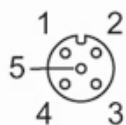

1	AS-i +
2	0V
3	AS-i -
4	+24V
5	ground fungsional