


E70005



Kabel koneksi


VSTA030MSS0002A02VDAB031--S

Produk tidak tersedia - entri arsip

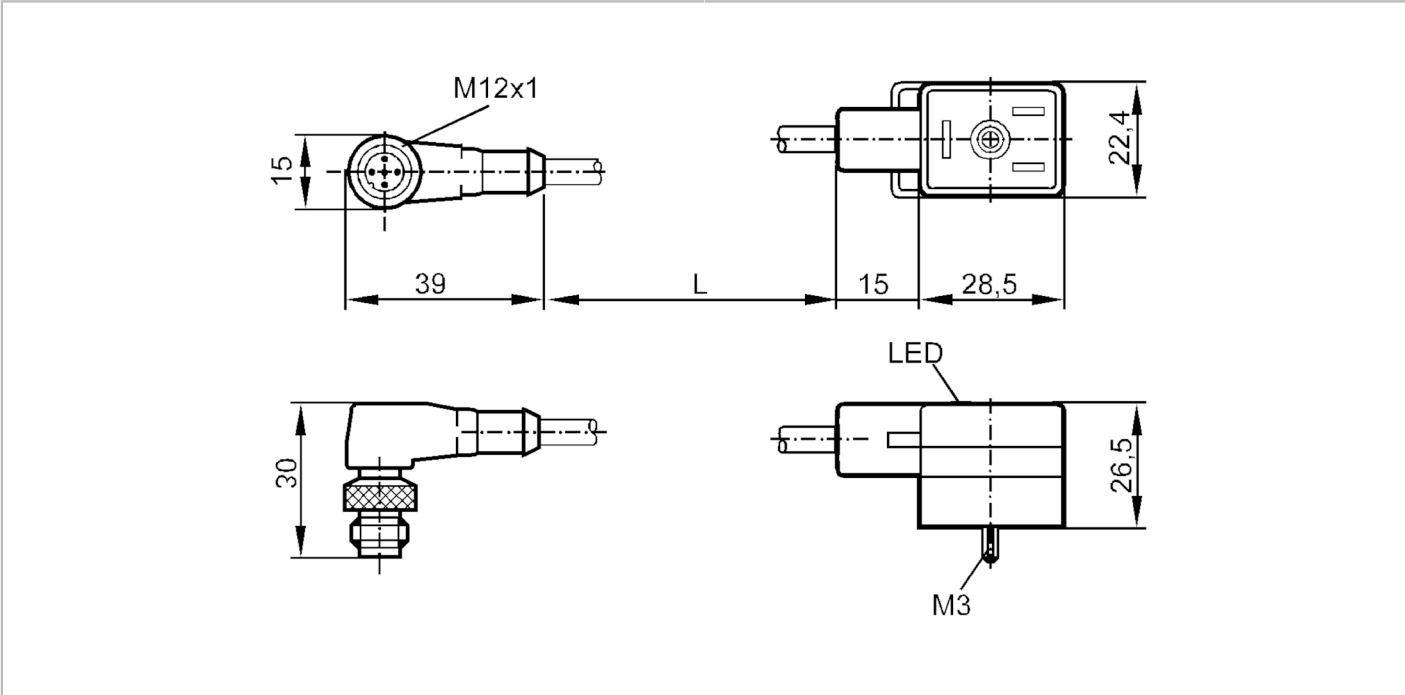

Data kelistrikan		
Tegangan pengoperasian	[V]	10...30 DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67
Data teknis		
Dimensi	[mm]	15 x 30 x 39
Material		PUR
Material bodi detakan		PUR
Material mur		kuningan, berlapis nikel
Aksesori		
Item dikirim		sekrup panel untuk pelabelan
Keterangan		
Jumlah paket		1 buah
Koneksi listrik - colokan		

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel

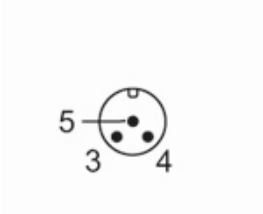




Kabel koneksi

VSTAH030MSS0002A02VDAB031--S

Koneksi listrik

Kabel: 2 m, PUR / PVC; 2 x

Koneksi

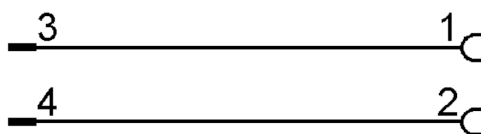

Koneksi listrik - soket

Konektor: 1 x katup tipe B DIN, bersiku; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel

