


Kabel koneksi

VDOG F030MSS0005A03STGH030MSS

Produk tidak tersedia - entri arsip

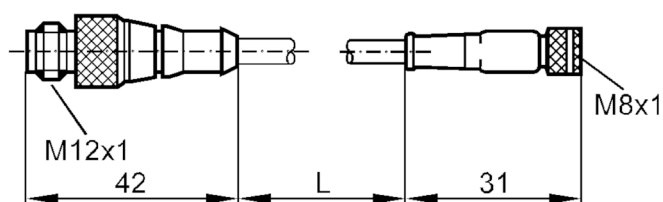

Data kelistrikan

Tegangan pengoperasian [V] 10...30 DC

Kelas perlindungan III

Kondisi pengoperasian

Suhu sekitar [°C] -25...90

Perlindungan IP 67

Data teknis

Material TPU

Material bodi detakan TPU

Material mur kuningan, berlapis nikel

Keterangan

Jumlah paket 1 buah

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel






Kabel koneksi

VDOGF030MSS0005A03STGH030MSS

Koneksi listrik

Kabel: 5 m, PUR / PVC; 3 x 0.34 mm²

Koneksi

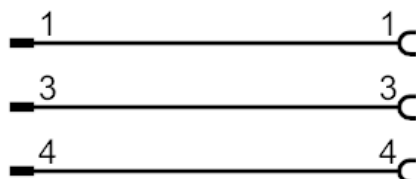

Koneksi listrik - soket

Konektor: 1 x M8, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

